




FQN10F25X03D, Fully Insulated Nylon Female Quick Disconnect For 12 - 10 AWG (.25 x .03)

By Burndy
Catalog # [FQN10F25X03D](#)

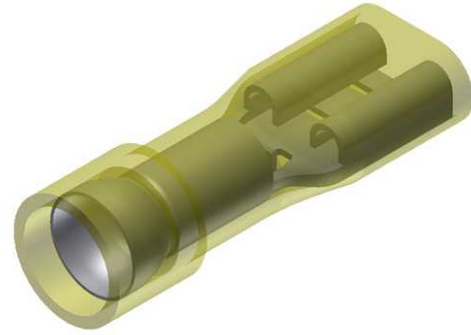

Fully Insulated Nylon Female Quick Disconnect For 12 - 10 AWG (.25 x .03).

Application

For quickly connecting or disconnecting a terminal

General

Connector Type	Female Quick Disconnect
EU RoHS Indicator	Yes
Insulation	Y
Insulation Type	Nylon
Material	Brass
Plated	Y
Plating Type	Tin
Sub Brand	FINGRIP
Trade Name	FINGRIP™
Type	Disconnect Connectors
UPC	781810293058
UPC 12 Digit	7818102930588

Dimensions

Dimension - Length Overall inch	0.98 in
Dimension - Strip Length inch	3/8 in
Dimension - Width inch	0.25 in
Dimension - Width mm	6 mm

Electrical Ratings

Voltage - Maximum	300 V
-------------------	-------

Conductor Related

Conductor - Copper Str Size	12 AWG;10 AWG
Conductor - Copper Str Size Range	12 AWG-10 AWG
Conductor Size	12 - 10 AWG
Conductor Type	CU C Str-Size

Certifications and Compliance

Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	Yes
Industry Standard(s)	UL467
Standards - Industry Standards Met	UL467
Standards - RoHS Compliance Status	CM
UL Listed	No

Logistics

Carton Quantity	300
Minimum Pack Quantity	25
Pallet Quantity	72000

Product Assets

[3D Models - FQN10F25X03D_MODEL-PDF](#)
[3D Models - FQN10F25X03D_MODEL-STEP](#)
[3D Models - FQN10F25X03D_MODEL-IGES](#)
[Catalogs - Full Line BURNDY Catalog](#)
[Customer Notices - Prop 65 Notice](#)
[Sales Drawings - 50094212](#)



A proud member of the Hubbell Family.

©2024 Hubbell Incorporated. All rights reserved.
BRDY-FQN10F25X03D-SPEC-EN | REV 1/2024