


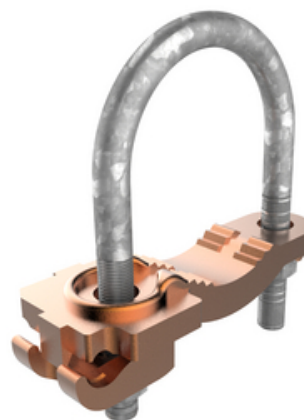

# GAR3904, Mechanical Grounding Connector, Conductor to Water Pipe

By Burndy  
Catalog # [GAR3904](#)

Mechanical Grounding Connector, Conductor to Water Pipe, 4-4/0 AWG, 2-1/2" - 3-1/2" Pipe , 3/8" Stud.



## General

Application	For Connecting A Small To Medium Range Copper Ground Conductor To Water Pipe As Well As Structural And Reinforcing Rod Shapes, Direct Burial Cables
Catalog Number	GAR3904
EU RoHS Indicator	Yes
Installation Torque Recommended in-lb	200 LBS/in
Material	Copper Alloy
Material - Hardware Plated	Galvanized Steel N
Plating Type	Unplated
Sub Brand	MECHANICAL CONNECTOR
Type	GAR3902
U Bolt Type	1033G
UPC	781810234037
UPC 12 Digit	7818102340377

## Dimensions

Dimension - B Length inch	1.75 in
Dimension - Height inch	6.50 in
Dimension - Length Overall inch	1.75 in
Dimension - Outside Diameter inch	4.00 in
Dimension - Width inch	6.00 in
Dimension - Width mm	152 mm

## Conductor Related

Conductor - Copper Solid Size Range	4 AWG - 4/0 AWG
Conductor - Copper Str Size	4;3;2;1;1/0;2/0;3/0;4/0
Conductor - Copper Str Size Range	4 AWG - 4/0 AWG
Conductor - Copper Tube Std Size	2 1/2;3 1/2
Conductor - Copper Tube Std Size Range	2 1/2-3 1/2
Conductor - Pipe or Round Tube Size	2.5 - 3.5 in

## Certifications And Compliance

Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Listed Direct Burial	Yes
Certification - UL Recognized	No
Certification - cULus	No
Industry Standard(s)	UL467
Standards - Industry Standards Met	UL467
Standards - RoHS Compliance Status	CM
UL Listed	Yes

## Logistics

Minimum Pack Quantity	1
-----------------------	---

## Product Assets

- [3D Models - GAR3904\\_MODEL-STEP](#)
- [3D Models - GAR3904\\_MODEL-IGES](#)
- [3D Models - GAR3904\\_MODEL-PDF](#)
- [Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)
- [Catalogs - BURNDY Master Catalog - Section E2 - Mechanical Grounding](#)
- [Customer Notices - Prop 65 Notice](#)
- [Interactive Catalog - BURNDY Full-Line Digital Catalog](#)
- [Product Cross Section Image\(s\) - BUR\\_GAR3900\\_Lineart](#)
- [Sales Drawings - SD206499-01](#)

