


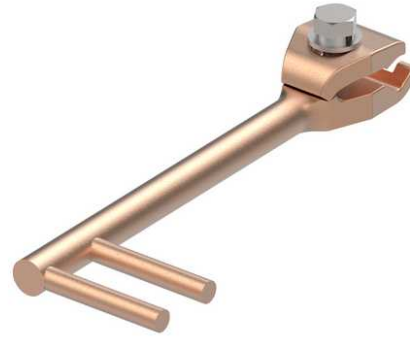

## GBG28G1, Cutout Extension

By Burndy  
Catalog # [GBG28G1](#)

Prongs attach to parallel groove clamp located at the bottom of the cutout and allows for the extension of the terminator. Connector end accommodates copper cable ranging from #4 sol. (0.204" dia.) to 4/0 str (0.552 dia.).



### General

Material Type - Screw	Steel - Stainless
Physical Attribute - Screw Type	Hexagonal Bolt
Plated	N
Plating Type	Unplated
UPC	781810096208
UPC 12 Digit	7818100962088

### Dimensions

Dimension - B Length inch	1.19 in
Dimension - Width fraction	7-1/8 in
Dimension - Width inch	7.12 in

### Conductor Related

Conductor - Copper Solid Size	4 AWG;3 AWG;2 AWG;1 AWG;1/0 AWG;2/0 AWG;3/0 AWG;4/0 AWG
Conductor - Copper Solid Size Range	4 AWG-4/0 AWG
Conductor - Copper Str Size	4 AWG;3 AWG;2 AWG;1 AWG;1/0 ;2/0 AWG;3/0 AWG;4/0 AWG
Conductor - Copper Str Size Range	4 AWG-4/0 AWG

### Certifications and Compliance

Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No
Standards - RoHS Compliance Status	EX
UL Listed	No

### Logistics

Minimum Pack Quantity	1
-----------------------	---

### Product Assets

[3D Models - GBG28G1\\_MODEL-STEP](#)  
[3D Models - GBG28G1\\_MODEL-IGES](#)  
[3D Models - GBG28G1\\_MODEL-PDF](#)  
[Catalogs - Full Line BURNDY Catalog](#)  
[Customer Notices - Prop 65 Notice](#)  
[Sales Drawings - SC084804-01](#)



A proud member of the Hubbell Family.

©2024 Hubbell Incorporated. All rights reserved.  
BRDY-GBG28G1-SPEC-EN | REV 1/2024