




# GC2525CTHEX314, Mechanical Grounding Connector, One to Two Cables to Bar

By Burndy  
Catalog # [GC2525CTHEX314](#)

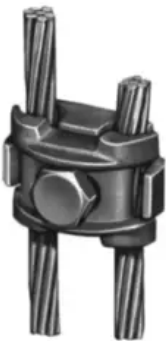

Accommodates: #6 Sol - 1/0 Str Cable (Copper or Aluminum);  
3/8" Galvanized Steel Hardware.

### General

Catalog Number	GC2525CTHEX314
Installation Torque	240 LBS/in
Recommended in-lb	
Material	Copper Alloy
Plated	Y
Plating Type	Tin
UPC	781810093443
UPC 14 Digit GTIN	00781810093443

### Dimensions

Dimension - B Length inch	1.12 in
Dimension - Cross Flats inch	0.56 in
Dimension - Height inch	1.95 in
Dimension - Height mm	49.5 mm
Dimension - Width inch	1.45 in
Dimension - Width mm	37 mm

### Conductor Related

Conductor - AL Str Size	6 AWG;4 AWG;3 AWG;2 AWG;1 AWG;1/0 AWG
Conductor - AL Str Size Range	6 AWG-1/0 AWG
Conductor - Copper Solid Size	6 AWG;5 AWG;4 AWG;3 AWG;2 AWG;1 AWG;1/0 AWG
Conductor - Copper Solid Size Range	6 AWG-1/0 AWG
Conductor - Copper Str Size	6 AWG;5 AWG;4 AWG;3 AWG;2 AWG;1 AWG;1/0

Conductor - Copper Str Size Range	6 AWG - 1/0 AWG
-----------------------------------	-----------------

### Certifications And Compliance

Buy America(n) Qualified	Contact Manufacturer
Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Listed Direct Burial	Yes
Certification - UL Recognized	No
Certification - cULus	No
Industry Standard(s)	UL467
Standards - Industry Standards Met	UL467
Standards - RoHS Compliance Status	EX
UL Listed	No

### Logistics

Minimum Pack Quantity	1
-----------------------	---

### Product Assets

- [Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)
- [Customer Notices - Prop 65 Notice](#)
- [Interactive Catalog - BURNDY Full-Line Digital Catalog](#)
- [Sales Drawings - 50091767](#)
- [Specifications - GC2525CTHEX314](#)



A Hubbell brand