


GIE2CG3, Mechanical Grounding Connector for Flexible Rubber Sheath Cable, 6-2 AWG

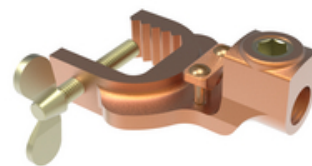

By Burndy
Catalog # [GIE2CG3](#)

Mechanical Grounding Connector, For Flexible Rubber Sheath Cable, 6 AWG - 2 AWG.

Application

For Used To Accommodates Flexible Rubber Sheath Cable Ranging From #6 - #2 Conductors

General

Catalog Number	GIE2CG3
EU RoHS Indicator	Yes
Material	Copper Alloy, Cast
Plated	N
Plating Type	Unplated
Sub Brand	MECHANICAL CONNECTOR
Type	GIE-G
UPC	781810052297
UPC 12 Digit	7818100522977

Dimensions

Dimension - Length Overall inch	4.31 in
Dimension - Width inch	3.06 in
Dimension - Width mm	78 mm

Conductor Related

Conductor Size	#6 AWG - #2 AWG
----------------	-----------------

Certifications And Compliance

Buy American Compliant	Yes
Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No
Standards - RoHS Compliance	EX
Status	
UL Listed	No

Logistics

Minimum Pack Quantity	1
-----------------------	---

Product Assets

- [3D Models - GIE2CG3_MODEL-PDF](#)
- [3D Models - GIE2CG3_MODEL-STEP](#)
- [3D Models - GIE2CG3_MODEL-IGES](#)
- [Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)
- [Catalogs - BURNDY Master Catalog - Section E2 - Mechanical Grounding](#)
- [Customer Notices - Prop 65 Notice](#)
- [Interactive Catalog - BURNDY Full-Line Digital Catalog](#)
- [Product Cross Section Image\(s\) - BUR_gieg2la](#)
- [Sales Drawings - 2114841](#)
- [Specifications - GIE2CG3](#)