




# GK6426, Copper Alloy Grounding Clamp, 3 Cables to Rod or Pipe

By Burndy  
Catalog # [GK6426](#)

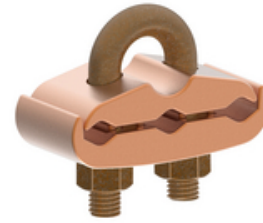

Mechanical Grounding Connector, 3 Cables to Rod or Pipe, 4 AWG (Sol.) - 2/0 AWG ( Str.), 3/8" Pipe, 5/8" - 3/4" Rod, 3/8" Stud.

## Application

For Joining Three Equal Copper Cables To Rod Or Tube, Direct Burial In Earth Or Concrete

## General

Catalog Number	GK6426
EU RoHS Indicator	Yes
Installation Torque Recommended in-lb	240 LBS/in
Material	Copper Alloy, Cast
Material Type - Screw Plated	DURIUM™ Silicon Bronze N
Plating Type	Unplated
Sub Brand	MECHANICAL CONNECTOR
Type	Three Cables to Rod or Tube
U Bolt Type	269
UPC	781810233528
UPC 12 Digit	7818102335288

## Dimensions

Bolt Size	3/8 in
Dimension - B Length inch	1.50 in
Dimension - Height inch	2.81 in
Dimension - Width inch	2.94 in
Dimension - Width mm	75 mm

## Conductor Related

Conductor - Rod Size	5/8 in ; 3/4 in
Conductor Size	#4 AWG Sol - 2/0 AWG Str

## Certifications And Compliance

Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Listed Direct Burial	Yes
Certification - UL Recognized	No
Certification - cULus	No
Industry Standard(s)	UL467
Standards - Industry Standards Met	UL467
Standards - RoHS Compliance Status	EX
UL Listed	Yes

## Logistics

Minimum Pack Quantity	1
-----------------------	---

## Product Assets

[3D Models - GK6426\\_MODEL-STEP](#)  
[3D Models - GK6426\\_MODEL-PDF](#)  
[3D Models - GK6426\\_MODEL-IGES](#)  
[Catalogs - Full Line BURNDY Catalog](#)  
[Catalogs - Section E2 - Mechanical Grounding](#)  
[Customer Notices - Prop 65 Notice](#)  
[Product Cross Section Image\(s\) - BUR\\_gk2la](#)  
[Sales Drawings - sc069674-01](#)



A proud member of the Hubbell Family.

©2024 Hubbell Incorporated. All rights reserved.  
BRDY-GK6426-SPEC-EN | REV 6/2024