


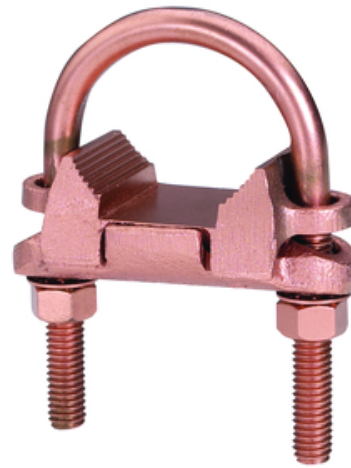

GP1726RT, Paint Penetrating Raised Floor Ground Clamp

By Burndy
Catalog # [GP1726RT](#)

Accommodates: (1) or (2) Conductors #6 - 2/0 Str Copper;
Torque: 245 in-lbs.



General

Material	Copper Alloy
Material - Hardware	DURIUM™ Silicon Bronze
Pedestal Type	Round;Square
Plated	N
Plating Type	Unplated
UPC	781810141779
UPC 12 Digit	7818101417799

Dimensions

Dimension - Height inch	3.86 in
Dimension - L Length Overall mm	38 mm
Dimension - Length Overall inch	1.50 in
Dimension - Width inch	3.22 in
Dimension - Width mm	82 mm

Conductor Related

Conductor Size	#6 AWG - 2/0 AWG STR
Number Of Conductors	1;2

Certifications and Compliance

Certification - CSA Approved	No
Industry Standard(s)	UL467
Standards - Industry Standards Met	UL467
Standards - RoHS Compliance Status	EX
UL Listed	Yes

Logistics

Minimum Pack Quantity	1
-----------------------	---

Product Assets

[3D Models - GP1726RT_MODEL-PDF](#)
[3D Models - GP1726RT_MODEL-IGES](#)
[3D Models - GP1726RT_MODEL-STEP](#)
[Catalogs - Full Line BURNDY Catalog](#)
[Customer Notices - Prop 65 Notice](#)
[Sales Drawings - SC..210786-01](#)



A proud member of the Hubbell Family.

©2024 Hubbell Incorporated. All rights reserved.
BRDY-GP1726RT-SPEC-EN | REV 1/2024