


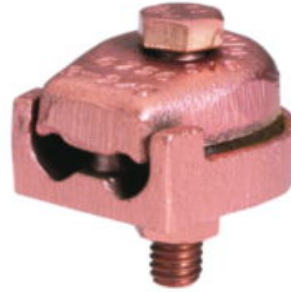

GZ2658, Mechanical Grounding Connector, Copper Cable to Bar

By Burndy
Catalog # [GZ2658](#)

Cast Cu Alloy Ground Clamp, Cable to Bar, #3 - 2/0 AWG Str, 5/8" Bolt



Application

For Joining A Wide Range Of Copper Cable To Bar, Direct Burial In Concrete Or Ground

General

Construction Material - Main	Copper
EU RoHS Indicator	Yes
Installation Torque Recommended in-lb	660 LBS/in
Material	Copper
Material Type - Screw Plated	DURIUM™ Silicon Bronze N
Plating Type	Unplated
Sub Brand	MECHANICAL CONNECTOR
Type	GZ
UPC	781810990148
UPC 12 Digit	7818109901488

Dimensions

Dimension - Height fraction	2-1/4
Dimension - Height inch	2.25 in
Dimension - L Length Overall mm	48 mm
Dimension - Length Overall inch	1.88 in
Dimension - Width fraction	1-3/4 in
Dimension - Width inch	1.75 in
Dimension - Width mm	44 mm

Conductor Related

Conductor - Copper Str Size	3;2;1;1/0;2/0
Conductor - Copper Str Size Range	3 AWG - 2/0 AWG

Certifications And Compliance

Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Listed Direct Burial	Yes
Certification - UL Recognized	No
Certification - cULus	No
Industry Standard(s)	UL467
Standards - Industry Standards Met	UL467
Standards - RoHS Compliance Status	EX
UL Listed	Yes

Product Assets

[Catalogs - Full Line BURNDY Catalog](#)
[Customer Notices - Prop 65 Notice](#)
[Product Cross Section Image\(s\) - BUR_gzla](#)
[Sales Drawings - SD208785-01](#)



A proud member of the Hubbell Family.

©2024 Hubbell Incorporated. All rights reserved.
BRDY-GZ2658-SPEC-EN | REV 5/2024