




GZ2958, Mechanical Grounding Connector

By Burndy
Catalog # [GZ2958](#)

Mechanical Grounding Connector, 3/0 AWG (Str) - 250 kcmil, 5/8" Stud.

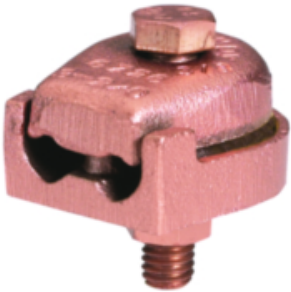

General

Installation Torque Recommended in-lb	660 in-lb
Material	Copper Alloy, Cast
Material Type - Screw Plated	DURIUM™ Silicon Bronze N
Plating Type	Unplated
UPC	781810260784
UPC 12 Digit	7818102607844

Dimensions

Bolt Size	5/8 in
Dimension - Bar Thickness inch	0.25 in
Dimension - Bar Thickness mm	6 mm
Dimension - Height fraction	2-1/2
Dimension - Height inch	2.50 in
Dimension - L Length Overall mm	59 mm
Dimension - Length Overall inch	2.34 in
Dimension - Width fraction	2-1/4 in
Dimension - Width inch	2.18 in
Dimension - Width mm	55 mm

Conductor Related

Conductor - Copper Str Size	3/0;4/0;250
Conductor - Copper Str Size Range	3/0 AWG - 250 kcmil
Conductor Range	#3/0 AWG (Str) - 250 kcmil

Certifications and Compliance

Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Listed Direct Burial	Yes
Certification - UL Recognized	No
Certification - cULus	No
Industry Standard(s)	UL467
Standards - Industry Standards Met	UL467
Standards - RoHS Compliance Status	EX
UL Listed	Yes

Logistics

Minimum Pack Quantity	6
-----------------------	---

Product Assets

[Catalogs - Full Line BURNDY Catalog](#)
[Customer Notices - Prop 65 Notice](#)
[Sales Drawings - SD208785-01](#)



A proud member of the Hubbell Family.