



GZ4C58, Mechanical Grounding Connector, Copper Cable to Bar

By Burndy
Catalog # [GZ4C58](#)

Mechanical Grounding Connector, 8 AWG (Str) - 4 AWG (Str), 5/8" Stud, Bar Thickness 1/4"

Features

- Rated for Direct Burial in earth or concrete
- UL 467 Listed for the US and Canadian Markets

Specifications


Certification - ETL	No
Certification - UL Recognized	No
Standards - Industry Standards Met	UL467
Standards - RoHS Compliance	EX
Status	
Certification - cULus	No
Certification - UL Listed Direct Burial	Yes
Buy America(n) Qualified	BABA Compliant (All status valid till December 2026)
Industry Standard(s)	UL467
UL Listed	Yes
Certification - CSA Approved	No

Conductor

Conductor Range	#8 AWG (Str) to #4 AWG (Str)
Conductor - Copper Str Size Range	8 AWG - 4 AWG
Conductor - Copper Str Size	• 8 • 7 • 6 • 5 • 4

Dimensions

Dimension - Bar Thickness mm	6 mm
Dimension - Bar Thickness inch	0.25 in
Package Height	0.000 in
Dimension - Height mm	50.8 mm
Dimension - Height inch	2 in
Dimension - Height fraction	2

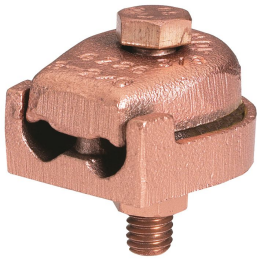

Package Weight	0.000 lb.
Dimension - Width mm	38 mm
Dimension - Width inch	1.50 in
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall mm	42 mm
Dimension - Width fraction	1-3/4 in
Bolt Size	5/8 in
Dimension - Length Overall inch	1.66 in

Force Related

Installation Torque Recommended	660 in-lb
---------------------------------	-----------

General

Plated	No
Product Family	Grounding and Bonding Connectors>Copper Mechanical Grounding Connectors>Cable(s) to Bar/Flat
Product Type	Mechanical
UPC	781810260760
Material Type - Screw	DURIUM™ Silicon Bronze
Material	Copper Alloy, Cast
Plating Type	Unplated
UPC 12 Digit	781810260760
UPC 14 Digit GTIN	00781810260760

Logistics

Minimum Pack Quantity	28
Pallet Quantity	1
Carton Quantity	1

Product Assets

[Catalog \[English\]](#)