




HT2C58, HammerTap Ground Rod Connection, #4 Str-#2 Str to 5/8" Ground Rod

By Burndy
Catalog # [HT2C58](#)

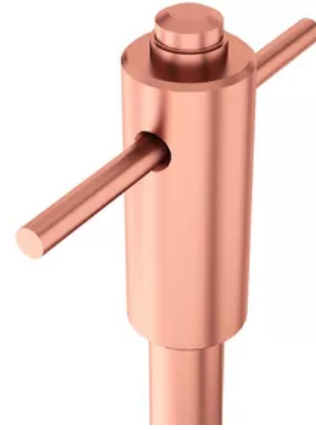

HammerTap Ground Rod Clamp, #4 Str-#2 Str to 5/8" Ground Rod, UL467 Listed for wire to ground rod. No spr training required for inecial tools ostallation, connection can be made easily using just a hammer. May be used as a termination or a "T" pass-through ground rod connection.

Features

- Irreversible connection option without having to weld
- Does not require special tools for installation
- Minimal training required
- Provides a visual verification that the connection is safely installed correctly
- Fast, easy, and safe connection capable of installation in any environment using just a hammer
- Versatile ground rod clamp, may be used as a termination or a "T" (pass-through) connection

Application

Termination or "T" (pass-through) Ground Rod Connection

General

Catalog Number	HT2C58
Connector Type	Grounding
Material	Copper
UPC	621945682108

Conductor Related

Conductor Type

- Cu C Sol-Size
- CU Str-Size

Certifications And Compliance

Industry Standard(s)

- UL 467
- Direct Burial
- CSA

Product Assets

[Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)
[Catalogs - BURNDY Master Catalog - Section E1 - Compression Grounding](#)

[Installation Manuals - Installation Instructions - HammerTap Ground Rod Connector](#)

[Interactive Catalog - BURNDY Full-Line Digital Catalog](#)

[Sales Drawings - 50130841](#)

[Sell Sheets - HammerTap Ground Rod Connector Flyer](#)
[Specifications - HT2C58](#)

[Video - BURNDY HammerTap Ground Rod Connector Installation](#)