


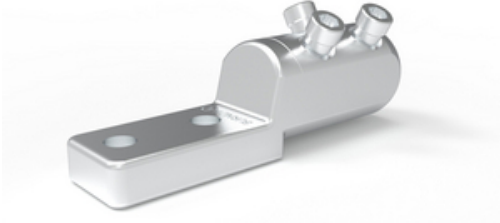

KASB44U2N, QIKSHEAR™ Shear Bolt Lug, 1000 kcmil 2-hole NEMA Drilled

By Burndy
Catalog # [KASB44U2N](#)

QIKSHEAR™ Shear Bolt Lug, 1000 kcmil 2-hole NEMA drilling, (2) 1/2 holes, 3/8 socket



Features

- No Tooling or Die Investment Required, no crimp tools necessary
- Dual Rated AL9CU for use with both copper and aluminum conductor
- cULus Listed Wire Connector to UL486A-486B
- Up to 35kV voltage rating
- Tin Plated aluminum connectors and bolts reduce galvanic corrosion and oxide build up
- Range-taking capabilities on most sizes

General

Hex Key	5/16"
Type	Bolted Lugs & Terminals
UPC	621945637504

Dimensions

Dimension - Pad Width inch	1.75
Dimension - Stud Size inch	1/2"
Length	6.95 in
Outside Diameter	2.01

Conductor Related

Wire Range	1000 kcmil (Class B & C)
------------	--------------------------

Logistics

Carton Quantity	14
Pallet Quantity	1260

Product Assets

[Catalogs - Full Line BURNDY Catalog](#)
[Installation Manuals - Shear Bolt Mechanical Connector Installation Instructions](#)
[Sales Drawings - 50109586](#)



A proud member of the Hubbell Family.