


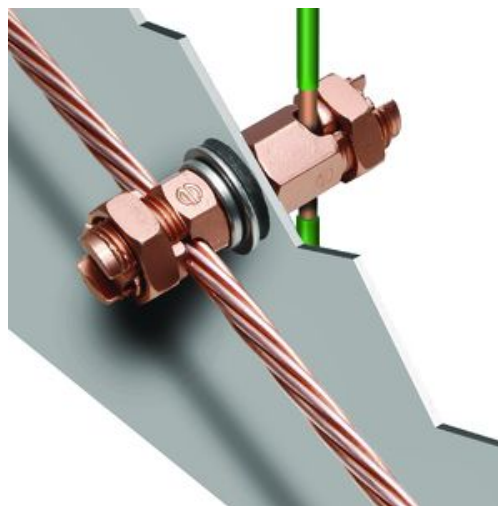

KCKF25, Mechanical Bulkhead Ground Connector Kit

By Burndy
Catalog # KCKF25

Mechanical Bulkhead Ground Connector Kit; Accommodates: #2 - 1/0 AWG Stranded, #2 - 2/0 Solid Copper; Nut Torque: 385 in-lbs



Application

Designed to allow a ground wire to be connected from the inside of a box or enclosure to the outside of a box or enclosure

General

Catalog Number	KCKF25
EU RoHS Indicator	Under Review
Material	Copper
Plated	N
Plating Type	Unplated
Stud Installation Torque inch pounds	150 LBS/in
Sub Brand	SERVIT POST
Trade Name	SERVIT POST™
Type	Bulkhead Servit
UPC	781810567449
UPC 12 Digit	7818105674499

Conductor Related

Conductor - Copper Solid Size	2 AWG;1 AWG;1/0 AWG;2/0 AWG
Conductor - Copper Solid Size Range	2 AWG-2/0 AWG
Conductor - Copper Str Size	2 AWG;1 AWG;1/0
Conductor - Copper Str Size Range	2 AWG-1/0 AWG

Certifications And Compliance

Buy American Compliant	No
Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No
Standards - RoHS Compliance Status	UI
UL Listed	Yes

Logistics

Carton Quantity	10
Minimum Pack Quantity	1
Pallet Quantity	4640

Product Assets

[Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)
[Catalogs - BURNDY Master Catalog - Section E2 - Mechanical Grounding](#)
[Customer Notices - Prop 65 Notice](#)
[Interactive Catalog - BURNDY Full-Line Digital Catalog](#)
[Sales Drawings - 50009515](#)
[Specifications - KCKF25](#)