


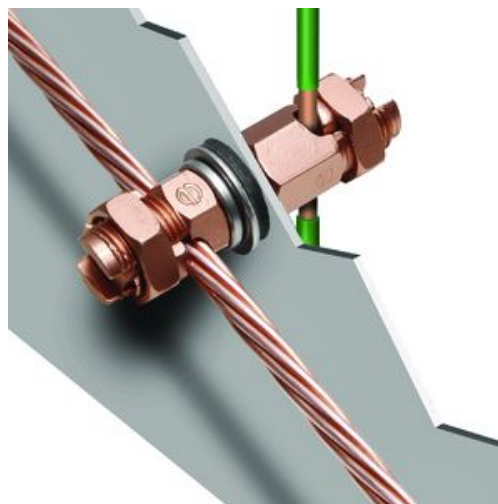

## KCKF28, Mechanical Bulkhead Ground Connector Kit

By Burndy  
Catalog # KCKF28

Mechanical Bulkhead Ground Connector Kit; Accommodates: #1 - 4/0 AWG Stranded, #1 - 4/0 AWG Solid Copper; Stainless Steel Split and Flat Washers; Neoprene Sealing Washer



### Application

Designed to allow a ground wire to be connected from the inside of a box or enclosure to the outside of a box or enclosure

### General

Catalog Number	KCKF28
EU RoHS Indicator	Under Review
Material	Copper
Plated	N
Plating Type	Unplated
Stud Installation Torque inch pounds	250 LBS/in
Sub Brand	SERVIT POST
Trade Name	SERVIT POST™
Type	Bulkhead Servit
UPC	781810635773
UPC 12 Digit	7818106357733

### Conductor Related

Conductor - Copper Solid Size	1 AWG;1/0 AWG;2/0 AWG;3/0 AWG;4/0 AWG
Conductor - Copper Solid Size Range	1 AWG-4/0 AWG
Conductor - Copper Str Size	1 AWG;1/0 ;2/0 AWG;3/0 AWG;4/0 AWG
Conductor - Copper Str Size Range	1 AWG-4/0 AWG

### Certifications And Compliance

Buy American Compliant	No
Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No
Standards - RoHS Compliance Status	EX
UL Listed	Yes

### Logistics

Minimum Pack Quantity	1
-----------------------	---

### Product Assets

- [Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)
- [Catalogs - BURNDY Master Catalog - Section E2 - Mechanical Grounding](#)
- [Customer Notices - Prop 65 Notice](#)
- [Interactive Catalog - BURNDY Full-Line Digital Catalog](#)
- [Sales Drawings - 50009515](#)
- [Specifications - KCKF28](#)