




# KK6A34U8, AL Universal Terminal, 6 Conductors, #2 AWG-500 kcmil, 8-Hole, Dual Rated

By Burndy  
Catalog # [KK6A34U8](#)

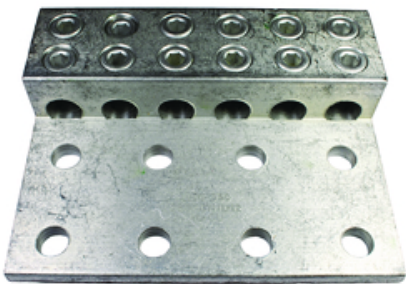

6 Conductors #2 AWG - 500 kcmil; Dual Rated.

### General

Connector Type	Parallel Set-Screw
Construction Material - Main	Aluminum
EU RoHS Indicator	Contact Manufacturer
Finish Type	Clear Plate Cms-14
Material	Aluminum
Number of Holes	8
Physical Attribute - Number of Holes	8
Plated	Y
Plating Type	Clear plated
Sub Brand	Universal Terminals
Type	Bolted Lugs & Terminals
UPC	781810666654

### Dimensions

Dimension - Bolt Size fraction	9/16
Dimension - Height inch	1.5 in
Dimension - L Length Overall mm	171 mm
Dimension - Length Overall inch	6.75 in
Dimension - Stud Size fraction	9/16

### Conductor Related

Conductor - AL Str Size Range	10 Str. - 500 Kcmil
Conductor - Copper Str Size Range	10 Str. - 500 Kcmil
Conductor Size	2 AWG-500 KCMIL
Conductor Type	<ul style="list-style-type: none"><li>• CU C Str-Size</li><li>• AL C Str-Size</li></ul>
Number Of Conductors	6
Number Of Wires	6

### Certifications and Compliance

Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No
Standards - RoHS Compliance Status	CM
UL Listed	No

### Logistics

Carton Quantity	12
Minimum Pack Quantity	1

### Product Assets

[Catalogs - Full Line BURNDY Catalog](#)  
[Customer Notices - Prop 65 Notice](#)  
[Sales Drawings - 50040581](#)



A proud member of the Hubbell Family.