


KK6A44U12, Universal Terminal, 6 Conductors, 350-1000 kcmil, 12-Hole, Dual Rated

By Burndy
Catalog # [KK6A44U12](#)

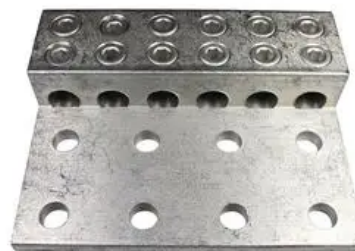

6 Conductors 350 - 1000 kcmil; Dual Rated.

Features

- Dual rated panelboard lugs constructed from high strength extruded aluminum alloy , electro tin-plated to provide low contact resistance

General

Catalog Number	KK6A44U12
Connector Type	Parallel Set-Screw
Construction Material - Main	Aluminum
EU RoHS Indicator	Contact Manufacturer
Finish Type	Clear Plate Cms-14
Material	Aluminum
Number of Holes	12
Physical Attribute - Number of Holes	12
Plated	Y
Plating Type	Clear plated
Sub Brand	Universal Terminals
Type	KK6A-U
UPC	781810666692

Dimensions

Dimension - Bolt Size fraction	9/16
Dimension - Height inch	1.88 in
Dimension - Height mm	47.8 mm
Dimension - L Length Overall mm	267 mm
Dimension - Length Overall inch	10.50 in
Dimension - Pad Width inch	3.44 in
Dimension - Stud Size fraction	9/16

Conductor Related

Conductor - AL Str Size Range	350 Kcmil - 1000 Kcmil
Conductor - Copper Str Size Range	350 Kcmil - 1000 Kcmil
Conductor Size	350-1000 KCMIL
Conductor Type	<ul style="list-style-type: none"> • CU C Str-Size • AL C Str-Size
Number Of Wires	6
Number of Conductors	6

Certifications And Compliance

Buy American Compliant	Contact Manufacturer
Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No
Standards - RoHS Compliance	CM
Status	
UL Listed	No

Logistics

Carton Quantity	6
Minimum Pack Quantity	1

Product Assets

- [Catalogs - BURNDY Master Catalog - Section A - Mechanical](#)
- [Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)
- [Customer Notices - Prop 65 Notice](#)
- [Interactive Catalog - BURNDY Full-Line Digital Catalog](#)
- [Sales Drawings - 50040595](#)
- [Specifications - KK6A44U12](#)