


KK8A31U10, Universal Terminal, 8 Conductors, #6 AWG-350 kcmil, Dual Rated

By Burndy
Catalog # [KK8A31U10](#)

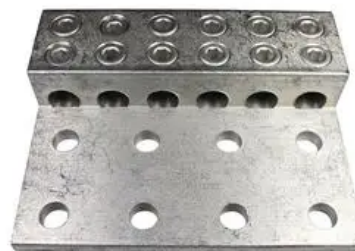

8 Conductors; #6 AWG - 350 kcmil; Dual Rated.

Features

- Dual rated panelboard lugs constructed from high strength extruded aluminum alloy , electro tin-plated to provide low contact resistance

General

Catalog Number	KK8A31U10
Connector Type	Parallel Set-Screw
Finish Type	Clear Plate
Material	Aluminum
Physical Attribute - Number of Holes	10
Plated	Y
Plating Type	Clear plated
Type	Bolted Lugs & Terminals
UPC	781810666647

Dimensions

Dimension - Bolt Size fraction	9/16
Dimension - Height inch	1.5 in
Dimension - Height mm	38.1 mm
Dimension - L Length Overall mm	222 mm
Dimension - Length Overall inch	8.75 in
Dimension - Pad Width inch	3.43 in
Dimension - Stud Size fraction	9/16

Conductor Related

Conductor - AL Str Size Range	12 Str. - 350 Kcmil
Conductor - Copper Str Size Range	12 Str. - 350 Kcmil
Conductor Size	6 AWG-350 KCMIL
Conductor Type	<ul style="list-style-type: none"> • CU C Str-Size • AL C Str-Size
Number Of Wires	8
Number of Conductors	8

Certifications And Compliance

Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No
Standards - RoHS Compliance Status	CM
UL Listed	No

Logistics

Carton Quantity	12
Minimum Pack Quantity	1

Product Assets

- [Catalogs - BURNDY Master Catalog - Section A - Mechanical](#)
- [Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)
- [Customer Notices - Prop 65 Notice](#)
- [Interactive Catalog - BURNDY Full-Line Digital Catalog](#)
- [Sales Drawings - 50040508](#)
- [Specifications - KK8A31U10](#)