




KK8A34U10, Universal Terminal, 8 Conductors, #2 AWG-500 kcmil, Dual Rated

By Burndy
Catalog # [KK8A34U10](#)

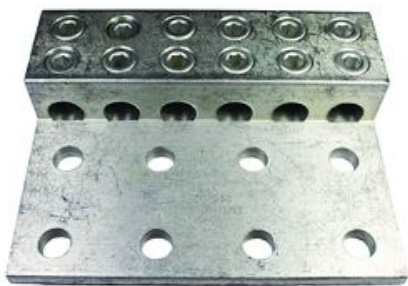

8 Conductors #2 AWG - 500 kcmil; Dual Rated.

Features

Dual rated panelboard lugs constructed from high strength extruded aluminum alloy , electro tin-plated to provide low contact resistance

General

Connector Type	Parallel Set-Screw
Construction Material - Main	Aluminum
EU RoHS Indicator	Contact Manufacturer
Finish Type	Clear Plate Cms-14
Material	Aluminum
Number of Holes	10
Physical Attribute - Number of Holes	10
Plated	Y
Plating Type	Clear plated
Sub Brand	Universal Terminals
Type	KK8A-U
UPC	781810666661

Dimensions

Dimension - Bolt Size fraction	9/16
Dimension - Height inch	1.5 in
Dimension - L Length Overall mm	222 mm
Dimension - Length Overall inch	8.75 in
Dimension - Pad Width inch	3.43 in
Dimension - Stud Size fraction	9/16

Conductor Related

Conductor - AL Str Size Range	10 Str. - 500 Kcmil
Conductor - Copper Str Size Range	10 Str. - 500 Kcmil
Conductor Size	2 AWG-500 KCMIL
Conductor Type	<ul style="list-style-type: none">• CU C Str-Size• AL C Str-Size
Number Of Wires	8
Number of Conductors	8

Certifications And Compliance

Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No
Standards - RoHS Compliance Status	CM
UL Listed	No

Logistics

Carton Quantity	12
Minimum Pack Quantity	1

Product Assets

[Catalogs - Full Line BURNDY Catalog](#)
[Customer Notices - Prop 65 Notice](#)
[Sales Drawings - 50040584](#)



A proud member of the Hubbell Family.