




KK8A34U10, Universal Terminal, 8 Conductors, #2 AWG-500 kcmil, Dual Rated

By Burndy
Catalog # [KK8A34U10](#)

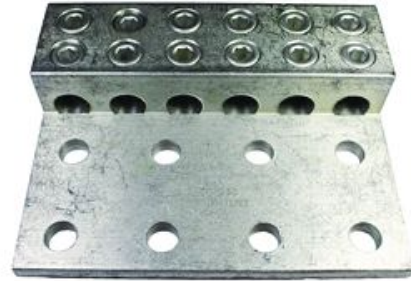

8 Conductors #2 AWG - 500 kcmil; Dual Rated.

Features

Dual rated panelboard lugs constructed from high strength extruded aluminum alloy, electro tin-plated to provide low contact resistance

General

| | |
|--------------------------------------|----------------------|
| Connector Type | Parallel Set-Screw |
| Construction Material - Main | Aluminum |
| EU RoHS Indicator | Contact Manufacturer |
| Finish Type | Clear Plate Cms-14 |
| Material | Aluminum |
| Number of Holes | 10 |
| Physical Attribute - Number of Holes | 10 |
| Plated | Y |
| Plating Type | Clear plated |
| Sub Brand | Universal Terminals |
| Type | KK8A-U |
| UPC | 781810666661 |

Dimensions

| | |
|---------------------------------|---------|
| Dimension - Bolt Size fraction | 9/16 |
| Dimension - Height inch | 1.5 in |
| Dimension - L Length Overall mm | 222 mm |
| Dimension - Length Overall inch | 8.75 in |
| Dimension - Pad Width inch | 3.43 in |
| Dimension - Stud Size fraction | 9/16 |

Conductor Related

| | |
|-----------------------------------|---|
| Conductor - AL Str Size Range | 10 Str. - 500 Kcmil |
| Conductor - Copper Str Size Range | 10 Str. - 500 Kcmil |
| Conductor Size | 2 AWG-500 KCMIL |
| Conductor Type | <ul style="list-style-type: none">• CU C Str-Size• AL C Str-Size |
| Number Of Wires | 8 |
| Number of Conductors | 8 |

Certifications And Compliance

| | |
|------------------------------------|----|
| Certification - CSA Approved | No |
| Certification - ETL | No |
| Certification - UL Recognized | No |
| Certification - cULus | No |
| Standards - RoHS Compliance Status | CM |
| UL Listed | No |

Logistics

| | |
|-----------------------|----|
| Carton Quantity | 12 |
| Minimum Pack Quantity | 1 |

Product Assets

[Catalogs - Full Line BURNDY Catalog](#)
[Customer Notices - Prop 65 Notice](#)
[Sales Drawings - 50040584](#)



A proud member of the Hubbell Family.

©2024 Hubbell Incorporated. All rights reserved.
BRDY-KK8A34U10-SPEC-EN | REV 5/2024