


# KK8A39U12, Universal Terminal, 8 Conductors, #2 AWG-750 kcmil, Dual Rated

By Burndy  
Catalog # [KK8A39U12](#)

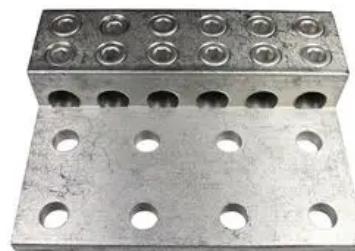

8 Conductors #2 AWG - 750 kcmil; Dual Rated.

## Features

- Dual rated panelboard lugs constructed from high strength extruded aluminum alloy , electro tin-plated to provide low contact resistance

## General

Catalog Number	KK8A39U12
Connector Type	Parallel Set-Screw
Construction Material - Main	Aluminum
EU RoHS Indicator	Contact Manufacturer
Finish Type	Clear Plate Cms-14
Material	Aluminum
Number of Holes	12
Physical Attribute - Number of Holes	12
Plated	Y
Plating Type	Clear plated
Sub Brand	Universal Terminals
Type	KK8A-U
UPC	781810666685

## Dimensions

Dimension - Bolt Size fraction	9/16
Dimension - Height inch	1.63 in
Dimension - Height mm	47.8 mm
Dimension - L Length Overall mm	267 mm
Dimension - Length Overall inch	10.50 in
Dimension - Pad Width inch	3.44 in
Dimension - Stud Size fraction	9/16

## Conductor Related

Conductor - AL Str Size Range	2 Str. - 750 Kcmil
Conductor - Copper Str Size Range	2 Str. - 750 Kcmil
Conductor Size	2 AWG-750 KCMIL
Conductor Type	<ul style="list-style-type: none"> <li>• CU C Str-Size</li> <li>• AL C Str-Size</li> </ul>
Number Of Wires	8
Number of Conductors	8

## Certifications And Compliance

Buy American Compliant	Contact Manufacturer
Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No
Standards - RoHS Compliance	CM
Status	
UL Listed	No

## Logistics

Carton Quantity	8
Minimum Pack Quantity	1

## Product Assets

- [Catalogs - BURNDY Master Catalog - Section A - Mechanical](#)
- [Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)
- [Customer Notices - Prop 65 Notice](#)
- [Interactive Catalog - BURNDY Full-Line Digital Catalog](#)
- [Sales Drawings - 50040591](#)
- [Specifications - KK8A39U12](#)