


KK8A44U14, Universal Terminal, 8 Conductors, 350-1000 kcmil, Dual Rated

By Burndy
Catalog # [KK8A44U14](#)

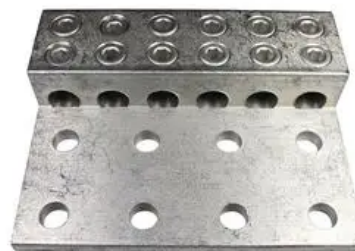

8 Conductors 350 - 1000 kcmil; Dual Rated.

Features

- Dual rated panelboard lugs constructed from high strength extruded aluminum alloy , electro tin-plated to provide low contact resistance

General

Catalog Number	KK8A44U14
Connector Type	Parallel Set-Screw
Finish Type	Clear Plate Cms-14
Installation Torque	550
Recommended in-lb	
Material	Aluminum
Plated	Y
Plating Type	Clear plated
Type	Bolted Lugs & Terminals
UPC	781810666708

Dimensions

Dimension - Bolt Size fraction	9/16
Dimension - D inch	6.19 in
Dimension - Height inch	1.88 in
Dimension - Height mm	47.8 mm
Dimension - Pad Width inch	12.12 in
Dimension - Stud Size fraction	9/16

Conductor Related

Conductor Size	350-1000 KCMIL
Number of Conductors	8

Certifications And Compliance

Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No
Standards - RoHS Compliance Status	CM
UL Listed	No

Logistics

Carton Quantity	6
Minimum Pack Quantity	1

Product Assets

- [Catalogs - BURNDY Master Catalog - Section A - Mechanical](#)
- [Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)
- [Customer Notices - Prop 65 Notice](#)
- [Interactive Catalog - BURNDY Full-Line Digital Catalog](#)
- [Sales Drawings - 50040598](#)
- [Specifications - KK8A44U14](#)