




# KS15NK, Split Bolt Connector, Run: #10 Str-#8 Sol, Tap: #14-#8 AWG, Nickel Plated

By Burndy  
Catalog # [KS15NK](#)

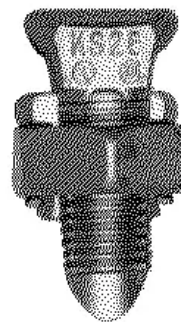

Cu Alloy SERVIT Split Bolt, #10 Str. - #8 Sol.(Run), #14 - #8 AWG(Tap), Nickel Plated.

## General

Catalog Number	KS15NK
Connector Type	Split Bolt
Material	Copper
Plated	Y
Plating Type	Nickel
Trade Name	SERVIT®
UPC	781810095584
UPC 12 Digit	7818100955844

- CU Weld C Str-Run
- CU C Solid-Tap
- CU C Str-Tap
- CU Weld C Str-Tap

## Dimensions

Dimension - Length Overall inch	0.85
Width	0.38 in

## Conductor Related

Conductor - Copper Solid Run	8 AWG
Conductor - Copper Solid Tap	8 AWG
Conductor - Copper Str Run Range	10 STR - 8 STR
Conductor - Copper Str Tap Range	10 STR - 8 STR
Conductor Type	<ul style="list-style-type: none"><li>• CU C Solid-Run</li><li>• CU C Str-Run</li></ul>

## Certifications And Compliance

Certification - CSA Approved	No
Industry Standard(s)	UL486D
Standards - Industry Standards Met	UL486D
Standards - RoHS Compliance Status	CM
UL Listed	Yes

## Logistics

Carton Quantity	100
Minimum Pack Quantity	1
Pallet Quantity	89100

## Product Assets

- [Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)
- [Customer Notices - Prop 65 Notice](#)
- [Interactive Catalog - BURNDY Full-Line Digital Catalog](#)
- [Sales Drawings - sd078561](#)
- [Specifications - KS15NK](#)