




KS17NK, Split Bolt Connector, Run: #8 Str-#6 Sol, Tap: #14-#6 Str, Nickel Plated

By Burndy
Catalog # [KS17NK](#)

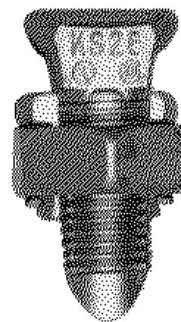

Cu Alloy SERVIT Split Bolt, #8 Str. - #6 Sol.(Run), #14 - #6 Str. (Tap), Nickel Plated.

General

Catalog Number	KS17NK
Connector Type	Split Bolt
Material	Copper
Plated	Y
Plating Type	Nickel
Trade Name	SERVIT®
UPC	781810089323
UPC 12 Digit	7818100893233

- CU C Str-Tap
- CU Weld C Str-Tap

Dimensions

Dimension - Length Overall inch	1.14
Width	0.45 in

Conductor Related

Conductor - Copper Solid Run	6 AWG
Conductor - Copper Solid Tap	6 AWG
Conductor - Copper Str Run Range	8 STR - 6 STR
Conductor - Copper Str Tap Range	8 STR - 6 STR
Conductor Type	<ul style="list-style-type: none">• CU C Solid-Run• CU C Str-Run• CU Weld C Str-Run• CU C Solid-Tap

Certifications And Compliance

Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No
Industry Standard(s)	UL486D
Standards - Industry Standards Met	UL486D
Standards - RoHS Compliance Status	CM
UL Listed	No

Logistics

Carton Quantity	100
Minimum Pack Quantity	1
Pallet Quantity	9900

Product Assets

- [Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)
- [Customer Notices - Prop 65 Notice](#)
- [Interactive Catalog - BURNDY Full-Line Digital Catalog](#)
- [Sales Drawings - sd078561](#)
- [Specifications - KS17NK](#)