


KS22TN, Split Bolt Connector, Run: #6-#2 AWG, Tap: #14-#2 AWG, Tin Plated

By Burndy
Catalog # [KS22TN](#)

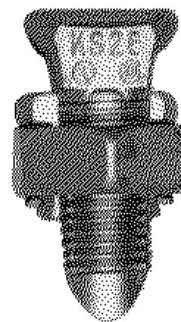

Cu Alloy SERVIT Split Bolt, #6 - #2 AWG(Run), #14 - #2 AWG(Tap), Tin Plated.

General

Catalog Number	KS22TN
Connector Type	Split Bolt
Material	Copper
Plated	Y
Plating Type	Tin Plated
Trade Name	SERVIT®
UPC	781810094129
UPC 12 Digit	7818100941299

- CU C Str-Tap
- CU Weld C Str-Tap

Dimensions

Dimension - Length Overall inch	1.5
Width	0.6 in

Conductor Related

Conductor - Copper Solid Run	2 AWG
Conductor - Copper Solid Tap	2 AWG
Conductor - Copper Str Run Range	6 STR - 3 STR
Conductor - Copper Str Tap Range	6 STR - 3 STR
Conductor Type	<ul style="list-style-type: none"> • CU C Solid-Run • CU C Str-Run • CU Weld C Str-Run • CU C Solid-Tap

Certifications And Compliance

Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No
Industry Standard(s)	UL486D
Standards - Industry Standards Met	UL486D
Standards - RoHS Compliance Status	CM
UL Listed	No

Logistics

Carton Quantity	100
Minimum Pack Quantity	100
Pallet Quantity	46400

Product Assets

- [Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)
- [Customer Notices - Prop 65 Notice](#)
- [Interactive Catalog - BURNDY Full-Line Digital Catalog](#)
- [Sales Drawings - sd078561](#)
- [Specifications - KS22TN](#)