


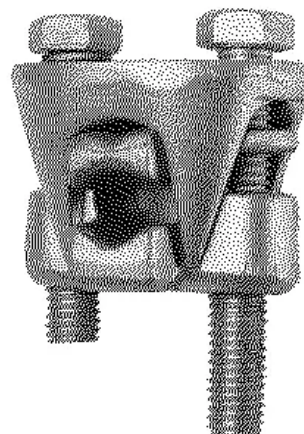

KVS40AS, 2-piece OKLIP Service Connector for heavy duty applications

By Burndy

Catalog # [KVS40AS](#)



Cast Al Alloy Mechanical OKLIP, 400 - 800 kcmil Cu/AAC,338.4 - 715.5 kcmil Al/ACSR(Run), 3/0 Str. - 800 kcmil Cu/AAC, 3/0 AWG - 715.5 kcmil Al/ACSR(Tap).

General

Catalog Number	KVS40AS
Material	Aluminum
Plated	N
Plating Type	Unplated
Trade Name	OKLIP™
UPC	781810125908
UPC 12 Digit	7818101259088

Conductor Related

Conductor Type	<ul style="list-style-type: none">• AL C Str-Run• CU C Str-Run• ACSR C Cmpt-Run• AAAC C 5005-Run• AAAC C 6201-Run• AL C Str-Tap• CU C Str-Tap• ACSR C Cmpt-Tap• AAAC C 5005-Tap• AAAC C 6201-Tap
----------------	---

Certifications And Compliance

Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No
Standards - RoHS Compliance	CM
Status	
UL Listed	Yes

Logistics

Minimum Pack Quantity	16
-----------------------	----

Product Assets

- [Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)
- [Customer Notices - Prop 65 Notice](#)
- [Interactive Catalog - BURNDY Full-Line Digital Catalog](#)
- [Product Cross Section Image\(s\) - BUR_kvsala](#)
- [Specifications - KVS40AS](#)



A Hubbell brand