




LF2027, Copper - Link Limiter, Pure Copper Link, LF, Amperage Rating: 250 AMP

By Burndy
Catalog # [LF2027](#)

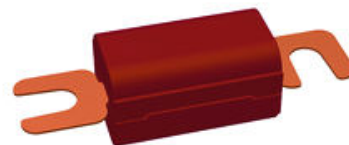

Pure Copper Link, LF, Amperage Rating: 250 AMP.

General

Catalog Number	LF2027
Connector Type	Limiter
Material	Copper
Plated	Y
Plating Type	Silver
UPC	781810000748
UPC 12 Digit	7818100007488

Dimensions

Dimension - D inch	0.32 in
Dimension - F Width Center to Center inch	0.42 in
Dimension - Length Overall inch	4.06 in
Dimension - Pad Width inch	3.06 in
Dimension - Width fraction	1 in
Dimension - Width inch	1 in

Electrical Ratings

Amperage Rating	250 A
-----------------	-------

Certifications And Compliance

Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No
Standards - RoHS Compliance Status	CM
UL Listed	No

Logistics

Carton Quantity	12
Minimum Pack Quantity	100
Pallet Quantity	5568

Product Assets

- [Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)
- [Catalogs - BURNDY Master Catalog - Section K - Underground](#)
- [Customer Notices - Prop 65 Notice](#)
- [Interactive Catalog - BURNDY Full-Line Digital Catalog](#)
- [Product Cross Section Image\(s\) - BUR_LF1010_LineArt](#)
- [Sales Drawings - 50014957](#)
- [SDS - DURICOMP SDS](#)
- [Specifications - LF2027](#)