




MD6 Hotstick Tool, Forged Steel Jaws O & D3, 72" Fiberglass Pole

By Burndy

Catalog # [MD68HS72](#)

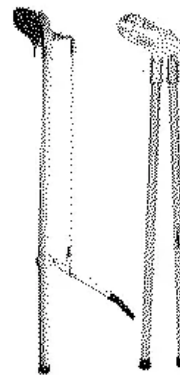

MD6 Hotstick Tool, O & D3 Grooves, 72" Fiberglass Pole.

Application

Crimping

General

Application - For Use On	Copper, Aluminum, ACSR, Steel, Copperweld, Alumoweld, 6201, 5005, Compressed and Compact Conductors
Catalog Number	MD68HS72
Crimp Force Capacity	4.5 ton
Die Type	W Die and X Die
Tool Type	Hot Stick
Trade Name	HYTOOL™
Type	Crimper
UPC	781810446270
UPC 12 Digit	7818104462700

Dimensions

Length	80.19 in
Weight	15.5 lb

Certifications And Compliance

Standards - RoHS Compliance Status	EX
------------------------------------	----

Logistics

Minimum Pack Quantity	1
Package Contents	Tool only

Product Assets

- [Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)
- [Customer Notices - Prop 65 Notice](#)
- [Interactive Catalog - BURNDY Full-Line Digital Catalog](#)
- [Product Cross Section Image\(s\) - BUR_MD68_LineArt](#)
- [Sales Drawings - 50001841](#)
- [Specifications - MD68HS72](#)



A Hubbell brand