




Uninsulated Male/Female Combination Quick Disconnect For 22 - 18 AWG (.25 x .03)

By Burndy
Catalog # [PG1825X03D](#)

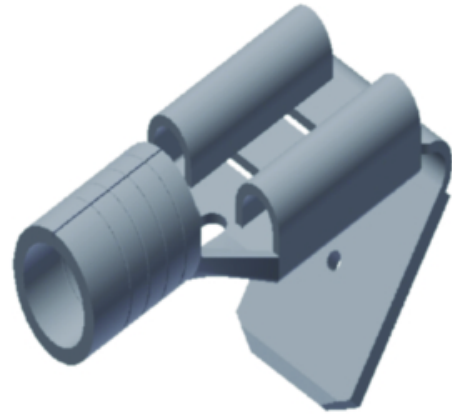

Uninsulated Male/Female Combination Quick Disconnect For
22 - 18 AWG (.25 x .03).

General

Connector Type	Male/Female Quick Disconnect
Material	Brass
Plated	Y
Plating Type	Tin
Type	Disconnect Connectors
UPC	781810530597
UPC 12 Digit	7818105305977

Dimensions

Dimension - B Length inch	0.17 in
Dimension - Length Overall inch	0.79 in
Dimension - Strip Length inch	3/8 in
Dimension - Width inch	0.25 in
Dimension - Width mm	6 mm

Conductor Related

Conductor Range	#22 AWG to #18 AWG
Conductor Size	22 - 18 AWG
Conductor Type	<ul style="list-style-type: none">• CU C Solid-Size• CU C Str-Size

Certifications and Compliance

Standards - RoHS Compliance UI
Status

Logistics

Minimum Pack Quantity 100

Product Assets

[3D Models - PG1825X03D_MODEL-PDF](#)
[3D Models - PG1825X03D_MODEL-STEP](#)
[3D Models - PG1825X03D_MODEL-IGES](#)
[Catalogs - Full Line BURNDY Catalog](#)
[Sales Drawings - 50094216](#)



A proud member of the Hubbell Family.

©2024 Hubbell Incorporated. All rights reserved.
BRDY-PG1825X03D-SPEC-EN | REV 1/2024