




Uninsulated Female Quick Disconnect For 16 - 14 AWG (.11 x .02)

By Burndy
Catalog # [Q14F11X02B](#)

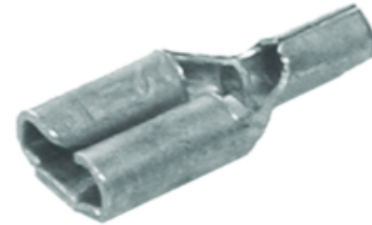

Uninsulated Female Quick Disconnect For 16 - 14 AWG (.11 x .02).

General

Connector Type	Female Quick Disconnect
Feature - Barrel Style	Chamfered
Material	Brass
Plated	Y
Plating Type	Tin
Trade Name	FINGRIP™
Type	Disconnect Connectors
UPC	781810355626
UPC 12 Digit	7818103556266

Dimensions

Dimension - Length Overall inch	0.66 in
Dimension - Strip Length inch	3/8 in
Dimension - Width inch	0.110 in
Dimension - Width mm	3 mm

Conductor Related

Conductor - Copper Str Size	16 AWG;14 AWG
Conductor - Copper Str Size Range	16 AWG - 14 AWG
Conductor Size	16 - 14 AWG
Conductor Type	<ul style="list-style-type: none">• CU C Solid-Size• CU C Str-Size

Certifications and Compliance

Standards - RoHS Compliance UI Status

Logistics

Minimum Pack Quantity 1000

Product Assets

[Catalogs - Full Line BURNDY Catalog](#)
[Sales Drawings - 50094205](#)



A proud member of the Hubbell Family.

©2024 Hubbell Incorporated. All rights reserved.
BRDY-Q14F11X02B-SPEC-EN | REV 1/2024