




## RDM628, Aluminum - Multiple Outlet Connector (RDM Mole)

By Burndy  
Catalog # [RDM628](#)

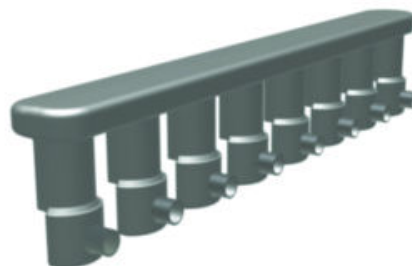

URD Mole, #4 Str. - 250 kcmil Al or Cu 300 kcmil - 350 kcmil ,  
600 Volt Rating, 8.78 in L.

### Application

For Aluminum And Copper And Direct Burial Or For Use In Enclosures

### General

Catalog Number	RDM628
Connector Type	Tap
EU RoHS Indicator	Yes
Insulation	Y
Insulation Type	Rubber
Material	Aluminum Alloy
Number Of Outlets	6
Sub Brand	URD MOLE
Trade Name	MOLE™
Type	RDM-28
UPC	781810180051
UPC 12 Digit	7818101800511

### Dimensions

Dimension - Length Overall inch	8.78 in
---------------------------------	---------

### Conductor Related

Conductor - AL Str Size	4 AWG;3 AWG;2 AWG;1 AWG;1/0 AWG;2/0 AWG;3/0 AWG;4/0 AWG;250 kcmil;266 kcmil;300 kcmil;336 kcmil;350 kcmil
Conductor - AL Str Size Range	4 AWG-350 kcmil
Conductor - Copper Str Size	4 AWG;3 AWG;2 AWG;1 AWG;1/0 ;2/0 AWG;3/0 AWG;4/0 AWG;250 kcmil
Conductor - Copper Str Size Range	4 AWG-250 kcmil

### Certifications And Compliance

Buy American Compliant	No
Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No
Standards - RoHS Compliance Status	CM
UL Listed	No

### Logistics

Minimum Pack Quantity	6
-----------------------	---

### Product Assets

- [Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)
- [Catalogs - BURNDY Master Catalog - Section K - Underground](#)
- [Customer Notices - Prop 65 Notice](#)
- [Interactive Catalog - BURNDY Full-Line Digital Catalog](#)
- [Product Cross Section Image\(s\) - BUR\\_RDM28\\_URDMOLE\\_LineArt](#)
- [Sales Drawings - SD060327-01\\_A](#)
- [Specifications - RDM628](#)