


SC4, Split Bolt Cover Kit

By Burndy
Catalog # SC4

Plastic Split Bolt Cover, Conductor range for equal Run/Tap: 8 str.-4 Sol.

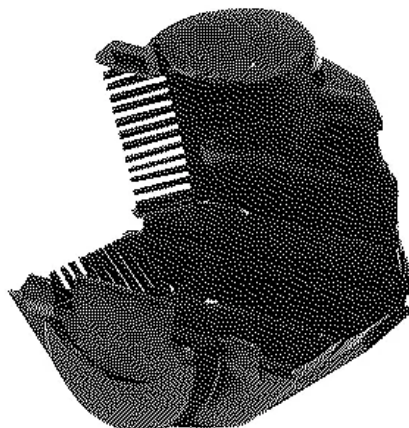

Features

- Type SC, SERVIT® Covers are applicable for indoor or outdoor use
- Compact, 1-piece cover saves time and material by eliminating costly taping of split-bolts
- Positive latch snaps quickly over connector and is ideal for tight quarters
- Self-positioning plastic fingers wrap around wires

Application

For Use In Indoors Or Outdoors Applications, KS17

General

Catalog Number	SC4
Connector Type	Split Bolt
EU RoHS Indicator	Contact Manufacturer
Material	Plastic
Sub Brand	SERVIT COVER
Temperature Rating	194
Trade Name	SERVIT®
Type	SC
UPC	781810042502

Dimensions

Dimension - Height mm	0 mm
-----------------------	------

Conductor Related

Conductor Size	8-4 AWG
----------------	---------

Certifications And Compliance

Buy American Compliant	Contact Manufacturer
Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No
Industry Standard(s)	UL 486A-486B
Standards - Industry Standards Met	UL 486A-486B
Standards - RoHS Compliance	CM
Status	
UL Listed	Yes

Logistics

Minimum Pack Quantity	1
-----------------------	---

Product Assets

[Catalogs - BURNDY Master Catalog - Section A - Mechanical](#)
[Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)
[Interactive Catalog - BURNDY Full-Line Digital Catalog](#)
[Product Cross Section Image\(s\) - BUR_G1FSC_LineArt](#)
[Sales Drawings - 55458](#)
[Specifications - SC4](#)