


Substation - Aluminum Rigid Spacer

By Burndy

Catalog # [SH2GBP41A512](#)

Cast Aluminum Bus Support 12 IN Spacer, 795 kcmil-874.5 kcmil AAC, 795 kcmil (45/7) ACSR.

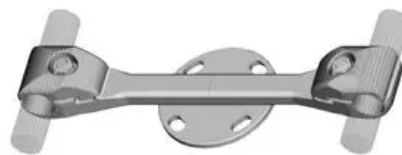

Application

Substation

General

Catalog Number	SH2GBP41A512
Connector Type	Bus Support Spacer
Material	Aluminum Alloy, Cast
Plated	N
Plating Type	Unplated
UPC	781810234143
UPC 12 Digit	7818102341433

Dimensions

Bolt Circle Diameter	5 in
Dimension - B Length inch	3.00 in
Dimension - G inch	1.50 in
Dimension - Height inch	2.85 in
Dimension - Height mm	72.4 mm
Dimension - L Length Overall mm	348 mm
Dimension - Length Overall inch	13.71 in
Dimension - Width inch	6.25 in
Dimension - Width mm	159 mm

Conductor Related

Conductor - ACSR Str Size	795 (54/7) Condor kcmil
---------------------------	-------------------------

Conductor - ACSR Str Size Range	795 (54/7) Condor kcmil
Conductor - AL Str Size	795 kcmil;800 kcmil;874 kcmil
Conductor - AL Str Size Range	795 kcmil-874 kcmil
Conductor - Connection Combination	Base to Cable
Number of Conductors	2

Certifications And Compliance

Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No
Standards - RoHS Compliance Status	EX
UL Listed	No

Logistics

Minimum Pack Quantity	9
-----------------------	---

Product Assets

[Catalogs - BURNDY Master Catalog - Section I - Transmission](#)
[Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)
[Interactive Catalog - BURNDY Full-Line Digital Catalog](#)
[Product Cross Section Image\(s\) - BUR_SH2GBPA_BUNDLED_SPACER_SUPP_LineArt](#)
[Specifications - SH2GBP41A512](#)