


## Substation - Aluminum Rigid Spacer

By Burndy  
Catalog # SH2GBP48A5

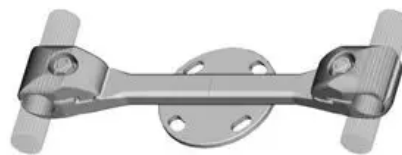

Cast Aluminum Bus Support 12 IN Spacer, 1750 kcmil-2000 kcmil AAC, 1590 (45/7) kcmil -1780 (84/19) kcmil ACSR.

### Application

Substation

### General

Catalog Number	SH2GBP48A5
Connector Type	Bus Support Spacer
Fitting Type	Slip or Rigid
Hardware Type	Cap mounting kit (w/o nuts)
Material	Aluminum Alloy, Cast
Material - Hardware	Aluminum Alloy
Mounting Hardware	5/8-11 x 1" GS
One Wrench Installation	Y
Physical Attribute - Number of Clamping Elements	1
Plated	N
Plating Type	Unplated
UPC	781810282274
UPC 12 Digit	7818102822744

### Dimensions

Bolt Circle Diameter	5 in
Dimension - B Length inch	3.00 in
Dimension - Diameter Max Size inch	1.632 in
Dimension - Diameter Min Size inch	1.504 in
Dimension - G inch	1.50 in
Dimension - Height inch	2.56 in
Dimension - Hole Size fraction	11/16
Dimension - Hole Size inch	0.69 in
Dimension - L Length Overall mm	457 mm
Dimension - Length Overall inch	18.00 in
Dimension - Width inch	6.25 in
Dimension - Width mm	159 mm

### Conductor Related

Conductor - ACSR Str Size	1590 (45/7) Lapwing kcmil;1590 (54/19) Falcon kcmil;1780 (54/19) kcmil;1780 (84/19) Chukar kcmil
Conductor - ACSR Str Size Range	1590 (45/7) Lapwing kcmil-1780 (84/19) Chukar kcmil
Conductor - AL Str Size	1750 kcmil;1800 kcmil;1900 kcmil;2000 kcmil
Conductor - AL Str Size Range	1750 kcmil-2000 kcmil
Conductor - Connection Combination	Base to Cable
Conductor Spacing	18 in
Number of Conductors	2

### Certifications And Compliance

Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No
Standards - RoHS Compliance Status	EX
UL Listed	No

### Logistics

Minimum Pack Quantity	1
-----------------------	---

### Product Assets

[Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)  
[Catalogs - BURNDY Master Catalog - Section I - Transmission](#)  
[Customer Notices - Prop 65 Notice](#)  
[Interactive Catalog - BURNDY Full-Line Digital Catalog](#)  
[Product Cross Section Image\(s\) - BUR\\_SH2GBPA\\_BUNDLED\\_SPACER\\_SUPP\\_LineArt](#)  
[Specifications - SH2GBP48A5](#)