


T106, Uninsulated Ring Terminal For 12 - 10 AWG

By Burndy
Catalog # T106

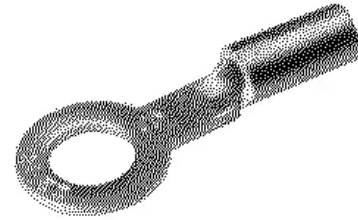

Uninsulated Ring Terminal For 12 - 10 AWG.

Features

Long neck terminal permits easy bending and stacking of several terminals on a common stud

General

Catalog Number	T106
Connector Type	Ring Terminal
Feature - Barrel Style	Chamfered
Material	Copper
Physical Attribute - Number of Holes	1
Physical Attribute - Tongue Type	Ring
Plated	Y
Plating Type	Tin - Electro Plated
Trade Name	HYLUG™
Type	Ring Tongue
UPC	781810722008
UPC 12 Digit	7818107220088

Dimensions

Dimension - Bolt Size fraction	#4 - #6
Dimension - L Length Overall mm	21 mm
Dimension - Length Overall inch	0.83 in
Dimension - Pad Width inch	0.37 in
Dimension - Strip Length inch	11/32
Dimension - Stud Size inch	#4;#5;#6
Dimension - Z (inch)	0.29 in

Conductor Related

Conductor - Copper Solid Size 12 AWG;11 AWG;10 AWG

Conductor - Copper Solid Size Range	12 AWG-10 AWG
Conductor - Copper Str Size	12 AWG;10 AWG
Conductor - Copper Str Size Range	12 AWG-10 AWG
Conductor Size	12 - 10 AWG
Conductor Type	<ul style="list-style-type: none"> • CU C Solid-Size • CU C Str-Size

Certifications And Compliance

Certification - CSA Approved	Yes
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No
Standards - Industry Standards Met	UL486
Standards - RoHS Compliance	CM
Status	
UL Listed	Yes

Logistics

Carton Quantity	600
Minimum Pack Quantity	50
Pallet Quantity	99999

Product Assets

[Catalogs - BURNDY Master Catalog - Section B - Small Compression](#)
[Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)
[Customer Notices - Prop 65 Notice](#)
[Interactive Catalog - BURNDY Full-Line Digital Catalog](#)
[Sales Drawings - 50094154](#)
[Specifications - T106](#)