




T1410, Uninsulated Ring Terminal For 16 - 14 AWG

By Burndy
Catalog # [T1410](#)

Uninsulated Ring Terminal For 16 - 14 AWG.

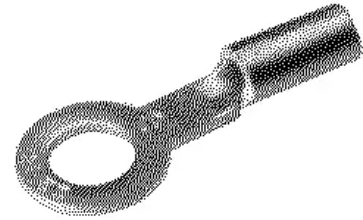

Features

Long neck terminal permits easy bending and stacking of several terminals on a common stud

Application

For Control Wiring And Other Standard Duty Applications

General

Catalog Number	T1410
Connector Type	Ring Terminal
EU RoHS Indicator	Yes
Feature - Barrel Type	Long
Material	Copper
Physical Attribute - Number of Holes	1
Physical Attribute - Tongue Type	Ring
Plated	Y
Plating Type	Tin - Electro Plated
Sub Brand	HYLUG
Trade Name	HYLUG™
Type	Ring Tongue
UPC	781810722442
UPC 12 Digit	7818107224422

Dimensions

Cable Insulation Diameter Maximum	0.08 in
Dimension - B Length fraction	13/50 in
Dimension - B Length inch	0.26 in
Dimension - Bolt Size fraction	#8 - #10
Dimension - Diameter Max Size inch	0.08 in
Dimension - Hole Size fraction	1/5
Dimension - Hole Size inch	0.20 in
Dimension - L Length Overall mm	20 mm
Dimension - Length Overall inch	0.77 in
Dimension - Pad Width inch	0.31 in
Dimension - Strip Length inch	9/32
Dimension - Stud Size inch	#8;#10
Dimension - Z (inch)	0.33 in

Conductor Related

Conductor - Copper Solid Size	20 ;18 AWG;17 AWG;16 AWG;15 AWG;14 AWG
Conductor - Copper Solid Size Range	20 -14 AWG
Conductor - Copper Str Size	20 AWG;18 AWG;16 AWG;14 AWG
Conductor - Copper Str Size Range	20 AWG - 14 AWG
Conductor Size	16 - 14 AWG
Conductor Type	<ul style="list-style-type: none">• CU C Str-Size• CU C Solid-Size

Certifications And Compliance

Buy American Compliant	Yes
Certification - CSA Approved	Yes
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No
Industry Standard(s)	UL467
Standards - Industry Standards Met	UL486
Standards - RoHS Compliance Status	CM
UL Listed	Yes

Logistics

Carton Quantity	1200
Minimum Pack Quantity	100
Pallet Quantity	99999

Product Assets

[3D Models - T1410_MODEL-IGES](#)
[3D Models - T1410_MODEL-STEP](#)
[3D Models - T1410_MODEL-PDF](#)
[Catalogs - BURNDY Master Catalog - Section B - Small Compression](#)
[Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)
[Customer Notices - Prop 65 Notice](#)
[Interactive Catalog - BURNDY Full-Line Digital Catalog](#)
[Product Cross Section Image\(s\) - BUR_K6FT_LineArt](#)
[Sales Drawings - 50094154](#)
[Specifications - T1410](#)



A Hubbell brand

©2024 Hubbell Incorporated. All rights reserved
BRDY-T1410-SPEC-EN | REV 10/2024