




VG1, Copper Alloy Vise Connector, #6-#10 Sol

By Burndy
Catalog # VG1

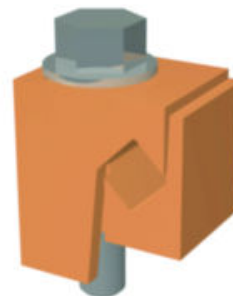

Cu Alloy Vise Connectors, #6 - #10 Sol.

General

| | |
|----------------|----------------|
| Catalog Number | VG1 |
| Connector Type | Stud Connector |
| Material | Copper |
| Plated | N |
| Plating Type | Unplated |
| Trade Name | WISEIT™ |
| UPC | 781810475119 |

Dimensions

| | |
|-----------------------------------|----------|
| Bolt Size | 3/8 in |
| Dimension - B Length fraction | 46/73 in |
| Dimension - B Length inch | 0.63 in |
| Dimension - Pad Width inch | 0.75 in |
| Dimension - Pin Diameter fraction | 47/50 in |
| Dimension - Pin Diameter inch | 0.94 in |

Conductor Related

| | |
|-------------------------------------|--------------------------------|
| Conductor - Copper Solid Run | #10 - #6 |
| Conductor - Copper Solid Run Range | #10 - #6 |
| Conductor - Copper Solid Size | 10 AWG;9 AWG;8 AWG;7 AWG;6 AWG |
| Conductor - Copper Solid Size Range | 10 AWG-6 AWG |
| Conductor - Copper Solid Tap | #10 - #6 |
| Conductor - Copper Solid Tap Range | #10 - #6 |
| Conductor - Copper Str Run | #10 - # 6 |
| Conductor - Copper Str Run Range | #10 - # 6 |
| Conductor - Copper Str Tap | #10 - #6 |
| Conductor - Copper Str Tap Range | #10 - #6 |

Certifications And Compliance

| | |
|-------------------------------|----|
| Certification - CSA Approved | No |
| Certification - ETL | No |
| Certification - UL Recognized | No |
| Certification - cULus | No |
| Standards - RoHS Compliance | CM |
| Status | |
| UL Listed | No |

Logistics

| | |
|-----------------------|-----|
| Carton Quantity | 500 |
| Minimum Pack Quantity | 100 |

Product Assets

- [Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)
- [Catalogs - BURNDY Master Catalog - Section H - Overhead Distribution](#)
- [Customer Notices - Prop 65 Notice](#)
- [Interactive Catalog - BURNDY Full-Line Digital Catalog](#)
- [Product Cross Section Image\(s\) - BUR_VG_LineArt](#)
- [Sales Drawings - 10090832](#)
- [Specifications - VG1](#)