


# Substation - Copper V Type T Connector

By Burndy  
Catalog # [VTT4646](#)

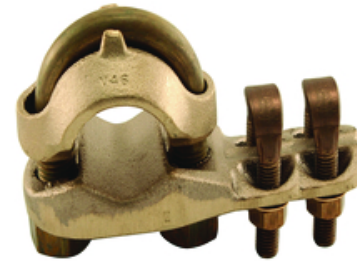

V Style Connectors.

## Application

Substation

## General

Connector Type	T-Connector
Material	Copper Alloy
Material - Hardware	DURIUM™ Silicon Bronze
One Wrench Installation	Y
Physical Attribute - Number of Run Conductors	1
Physical Attribute - Number of Tap Conductors	1
Plated	N
Plating Type	Unplated
Type	Bolted Tees
UPC	621945458093
UPC 12 Digit	6219454580933

## Dimensions

Dimension - Height inch	3.81 in
Dimension - L Length Overall mm	197 mm
Dimension - Length Overall inch	7.75 in
Dimension - Width inch	3.25 in
Dimension - Width mm	83 mm

## Conductor Related

Conductor - Connection Combination	Cable to Cable
Conductor - Copper Str Run	1000 kcmil;1250 kcmil;1300 kcmil;1500 kcmil
Conductor - Copper Str Run Range	1000 kcmil-1500 kcmil
Conductor - Copper Str Tap	1000 kcmil;1250 kcmil;1300 kcmil;1500 kcmil
Conductor - Copper Str Tap Range	1000 kcmil-1500 kcmil

## Certifications and Compliance

Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No
Standards - RoHS Compliance Status	EX
UL Listed	Yes

## Logistics

Minimum Pack Quantity	1
-----------------------	---

## Product Assets

[Customer Notices - Prop 65 Notice](#)  
[Sales Drawings - sa004362-01](#)