


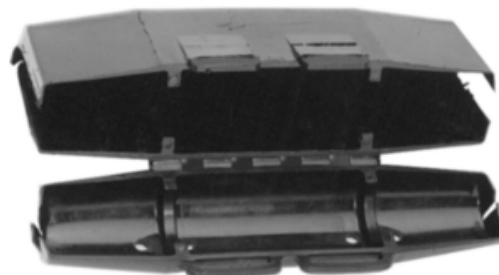

## WCCB, WEJTAP Cover

By Burndy  
Catalog # [WCCB](#)

Wejtap Cover, 2 AWG-300 kcmil (Run), 6 AWG-300 kcmil (Tap),  
Cover Color-Black Weather Rated.



### Application

For Blue And Red WEJTAP Connector

### General

Catalog Number	WCCB
Color	Black
EU RoHS Indicator	Yes
Material	Plastic
Sub Brand	WEJTAP
Trade Name	WEJTAP™
Type	Wejtap Cover
UPC	781810871249
UPC 12 Digit	7818108712499

## Conductor Related

Conductor - ACSR Str Run	2 (7/1) Sparate AWG;1 (6/1) Robin AWG;1/0 (6/1) Raven AWG;2/0 (6/1) Quail AWG;3/0 (6/1) Pigeon AWG;4/0 (6/1) Penguin AWG;80 (8/1) Grouse kcmil;101.8 (12/7) Petrel kcmil;110.8 (12/7) Minorca kcmil;134.6 (12/7) Leghorn kcmil;159 (12/7) Guinea kcmil;176.9 (12/7) Dotterel kcmil;190.8 (12/7) Dorking kcmil;211.3 (12/7) Cochin kcmil;203.2 (16/9) Brahma kcmil;266.8 (18/1) Waxwing kcmil;266.8 (26/7) Owl kcmil;266.8 (26/7) Partridge kcmil;300.0 (26/7) Ostrich kcmil
Conductor - ACSR Str Run Range	2 (7/1) Sparate AWG-300.0 (26/7) Ostrich kcmil
Conductor - ACSR Str Tap	6 (6/1) Turkey AWG;5 (6/1) Thrush AWG;4 (6/1) Swan AWG;4 (7/1) Swanate AWG;3 (6/1) Swallow AWG;2 (6/1) Sparrow AWG;2 (7/1) Sparate AWG;1 (6/1) Robin AWG;1/0 (6/1) Raven AWG;2/0 (6/1) Quail AWG;3/0 (6/1) Pigeon AWG;4/0 (6/1) Penguin AWG;80 (8/1) Grouse kcmil;101.8 (12/7) Petrel kcmil;110.8 (12/7) Minorca kcmil;134.6 (12/7) Leghorn kcmil;159 (12/7) Guinea kcmil;176.9 (12/7) Dotterel kcmil;190.8 (12/7) Dorking kcmil;211.3 (12/7) Cochin kcmil;203.2 (16/9) Brahma kcmil;266.8 (18/1) Waxwing kcmil;266.8 (26/7) Owl kcmil;266.8 (26/7) Partridge kcmil;300.0 (26/7) Ostrich kcmil
Conductor - ACSR Str Tap Range	6 (6/1) Turkey AWG-300.0 (26/7) Ostrich kcmil
Conductor - AL Str Run	2 AWG;1 AWG;1/0 AWG;2/0 AWG;3/0 AWG;4/0 AWG;250 kcmil;266 kcmil;300 kcmil
Conductor - AL Str Run Range	2 AWG-300 kcmil
Conductor - AL Str Tap	6 AWG;4 AWG;3 AWG;2 AWG;1 AWG;1/0 AWG;2/0 AWG;3/0 AWG;4/0 AWG;250 kcmil;266 kcmil;300 kcmil
Conductor - AL Str Tap Range	6 AWG-300 kcmil
Conductor - Copper Solid Run	2 AWG;1 AWG;1/0 AWG;2/0 AWG;3/0 AWG;4/0 AWG
Conductor - Copper Solid Run Range	2 AWG-4/0 AWG
Conductor - Copper Solid Tap	6 AWG;5 AWG;4 AWG;3 AWG;2 AWG;1 AWG;1/0 AWG;2/0 AWG;3/0 AWG;4/0 AWG
Conductor - Copper Solid Tap Range	6 AWG-4/0 AWG

Conductor - Copper Str Run	2 AWG;1 AWG;1/0 ;2/0 AWG;3/0 AWG;4/0 AWG;250 kcmil;300 kcmil
Conductor - Copper Str Run Range	2 AWG-300 kcmil
Conductor - Copper Str Tap	6 AWG;5 AWG;4 AWG;3 AWG;2 AWG;1 AWG;1/0 ;2/0 AWG;3/0 AWG;4/0 AWG;250 kcmil;300 kcmil
Conductor - Copper Str Tap Range	6 AWG-300 kcmil
Conductor Type	<ul style="list-style-type: none"><li>AL C Str-Run</li><li>CU C Str-Run</li><li>AL C Str-Tap</li><li>CU C Str-Tap</li></ul>

## Certifications And Compliance

Buy American Compliant	Yes
Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No
Standards - RoHS Compliance Status	CM
UL Listed	No

## Logistics

Minimum Pack Quantity	1
-----------------------	---

## Product Assets

- [3D Models - WCCB\\_MODEL-PDF](#)
- [3D Models - WCCB\\_MODEL-STEP](#)
- [3D Models - WCCB\\_MODEL-IGES](#)
- [Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)
- [Catalogs - BURNDY Master Catalog - Section J - OH Distribution / Transmission](#)
- [Interactive Catalog - BURNDY Full-Line Digital Catalog](#)
- [Product Cross Section Image\(s\) - BUR\\_WCCB\\_LineArt](#)
- [Sales Drawings - 50015383](#)
- [Sell Sheets - WEJTAP Group](#)
- [Specifications - WCCB](#)



A Hubbell brand