




WILEYBRAID12-516, Cu Braid, 12.00 IN L, 0.709 IN W, M8 or 5/16" Hardware NOT included

By Burndy
Catalog # [WILEYBRAID12-516](#)

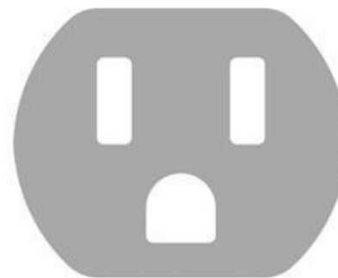

Oh No!
IMAGE COMING SOON

Cu Braid, 12.00 IN L, 0.709 IN W, .32 IN Hole Dia

General

Catalog Number	WILEYBRAID12-516
Item Type	3B
Trade Name	WILEY
UPC	621945448391
UPC 12 Digit	6219454483911

Dimensions

Bolt Size	5/16 in
Dimension - Thread Size	-

Certifications And Compliance

Certification - CSA Approved	N
Certification - ETL	Y
Certification - UL Recognized	N
Certification - cULus	N
Certified Listed	UL2703
Industry Standard(s)	UL2703

Standards - RoHS Compliance	CM
Status	
UL Listed	Yes

Logistics

Carton Quantity	100
Pallet Quantity	9000

Product Assets

- [Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)
- [Catalogs - BURNDY Master Catalog - Section E4 - Wiley Grounding](#)
- [Certifications - UL Certificate of Compliance, UL 2703](#)
- [Certifications - UL Standard for Safety for Grounding & Bonding Equipment, UL 467, CSA C22.2 No. 41-13](#)
- [Customer Notices - Prop 65 Notice](#)
- [Interactive Catalog - BURNDY Full-Line Digital Catalog](#)
- [Sales Drawings - 50059512](#)
- [Specifications - WILEYBRAID12-516](#)