



# WILEYBRAID30-38, Cu Braid, 30.00 IN L, 0.87 IN W, M10 or 3/8" Hardware NOT included

By Burndy  
Catalog # [WILEYBRAID30-38](#)

WILEY Bonding Jumpers are perfect for tracker applications, galvanized steel, or anywhere a WEEB® washer is not required.

## Application

The corrosion resistant, tin plated copper Wiley line of bonding jumpers are high quality solutions for your system to create an electrical bond between two pieces of galvanized or other uncoated electrically conductive metals. Standard lengths range from 6" to 36", with or without installation hardware assembled or unassembled. Custom lengths are also available on request. UL467 and UL2703 Listed.


## General

Catalog Number                   WILEYBRAID30-38  
UPC                                   621945461536

## Dimensions

Bolt Size                            3/8 in

## Certifications And Compliance

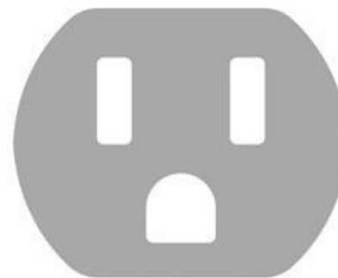

**Oh No!**  
IMAGE COMING SOON

Certified Listed	UL2703
Industry Standard(s)	UL2703
UL Listed	Yes

## Logistics

Carton Quantity	25
Pallet Quantity	4200

## Product Assets

- [Catalogs - BURNDY Master Catalog - Section E4 - Wiley Grounding](#)
- [Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)
- [Certifications - UL Standard for Safety for Grounding & Bonding Equipment, UL 467, CSA C22.2 No. 41-13](#)
- [Certifications - UL Certificate of Compliance, UL 2703](#)
- [Customer Notices - Prop 65 Notice](#)
- [Interactive Catalog - BURNDY Full-Line Digital Catalog](#)
- [Sales Drawings - 50061797](#)
- [Specifications - WILEYBRAID30-38](#)