



WILEYBRAID36, Cu Braid , 36.00 IN L, 0.709 IN W, M6 or 1/4" Hardware NOT included

By Burndy
Catalog # WILEYBRAID36

Wiley Braid; 36" Tin Plated.

Application

The corrosion resistant, tin plated copper Wiley line of bonding jumpers are high quality solutions for your system to create an electrical bond between two pieces of galvanized or other uncoated electrically conductive metals. Standard lengths range from 6" to 36", with or without installation hardware assembled or unassembled. Custom lengths are also available on request. UL467 and UL2703 Listed.

General


Catalog Number	WILEYBRAID36
Item Type	3C
Trade Name	WILEY
UPC	781810565636
UPC 12 Digit	7818105656366

Dimensions

Bolt Size	1/4 in
Dimension - Thread Size	-

Certifications And Compliance

Certification - CSA Approved	N
------------------------------	---

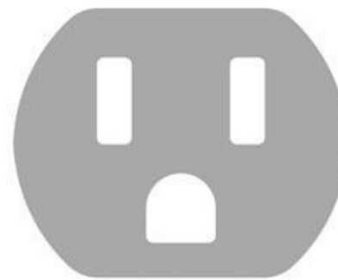

Oh No!
IMAGE COMING SOON

Certification - ETL	Y
Certification - UL Recognized	N
Certification - cULus	N
Certified Listed	UL2703
Industry Standard(s)	UL2703
Standards - RoHS Compliance	CM
Status	
UL Listed	Yes

Logistics

Carton Quantity	25
Pallet Quantity	4200

Product Assets

- [Catalogs - BURNDY Master Catalog - Section E4 - Wiley Grounding](#)
- [Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)
- [Certifications - UL Standard for Safety for Grounding & Bonding Equipment, UL 467, CSA C22.2 No. 41-13](#)
- [Certifications - UL Certificate of Compliance, UL 2703](#)
- [Customer Notices - Prop 65 Notice](#)
- [Interactive Catalog - BURNDY Full-Line Digital Catalog](#)
- [Sales Drawings - 50028922](#)
- [Specifications - WILEYBRAID36](#)