



## WILEYBRAID6-38, Cu Braid, 38.00 IN L, 0..87 IN W, M10 or 3/8" Hardware NOT included

By Burndy  
Catalog # [WILEYBRAID6-38](#)

WILEY Bonding Jumpers are perfect for tracker applications, galvanized steel, or anywhere a WEEB® washer is not required.

### Application


The corrosion resistant, tin plated copper Wiley line of bonding jumpers are high quality solutions for your system to create an electrical bond between two pieces of galvanized or other uncoated electrically conductive metals. Standard lengths range from 6" to 36", with or without installation hardware assembled or unassembled. Custom lengths are also available on request. UL467 and UL2703 Listed.

### General

Catalog Number	WILEYBRAID6-38
Item Type	3C
UPC	621945448339
UPC 12 Digit	6219454483399

### Dimensions

Bolt Size	3/8 in
Dimension - Length Overall inch	6 in
Dimension - Thread Size	-

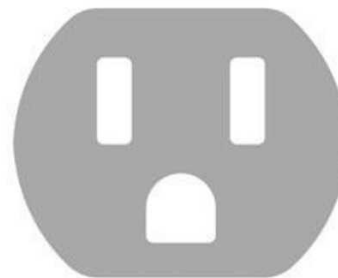

**Oh No!**  
IMAGE COMING SOON

### Certifications And Compliance

Certified Listed	UL2703
Industry Standard(s)	UL2703
UL Listed	Yes

### Logistics

Carton Quantity	100
Pallet Quantity	10500

### Product Assets

- [Catalogs - BURNDY Master Catalog - Section E4 - Wiley Grounding](#)
- [Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)
- [Certifications - UL Standard for Safety for Grounding & Bonding Equipment, UL 467, CSA C22.2 No. 41-13](#)
- [Certifications - UL Certificate of Compliance, UL 2703](#)
- [Customer Notices - Prop 65 Notice](#)
- [Interactive Catalog - BURNDY Full-Line Digital Catalog](#)
- [Sales Drawings - 50060880](#)
- [Specifications - WILEYBRAID6-38](#)