



## WILEYBRAID6-516, Cu Braid, 6.00 IN L, 0.709 IN W, M8 or 5/16" Hardware NOT included

By Burndy

Catalog # [WILEYBRAID6-516](#)

WILEY Bonding Jumpers are perfect for tracker applications, galvanized steel, or anywhere a WEEB® washer is not required.

### Application

The corrosion resistant, tin plated copper Wiley line of bonding jumpers are high quality solutions for your system to create an electrical bond between two pieces of galvanized or other uncoated electrically conductive metals. Standard lengths range from 6" to 36", with or without installation hardware assembled or unassembled. Custom lengths are also available on request. UL467 and UL2703 Listed.


### General

Catalog Number	WILEYBRAID6-516
Item Type	3B
Trade Name	WILEY
UPC	621945448407
UPC 12 Digit	6219454484077

### Dimensions

Bolt Size	5/16 in
Dimension - Thread Size	-

### Certifications And Compliance

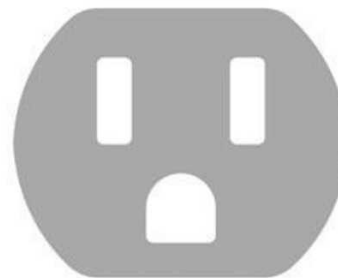

**Oh No!**  
IMAGE COMING SOON

Certification - ETL	Y
Certified Listed	UL2703
Industry Standard(s)	UL2703
UL Listed	Yes

### Logistics

Carton Quantity	100
Pallet Quantity	10500

### Product Assets

- [Catalogs - BURNDY Master Catalog - Section E4 - Wiley Grounding](#)
- [Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)
- [Certifications - UL Standard for Safety for Grounding & Bonding Equipment, UL 467, CSA C22.2 No. 41-13](#)
- [Certifications - UL Certificate of Compliance, UL 2703](#)
- [Customer Notices - Prop 65 Notice](#)
- [Interactive Catalog - BURNDY Full-Line Digital Catalog](#)
- [Sales Drawings - 50060537](#)
- [Specifications - WILEYBRAID6-516](#)



A Hubbell brand