


# Compression Splice Reducer

By Burndy  
Catalog # Y286CR

4/0 AWG CU Long Barrel Size Reduced Down To 6 AWG Wire Size, Internal Chamfer, Tin Plated, Up to 35kV, PURPLE Color Code, 15 Die Index.

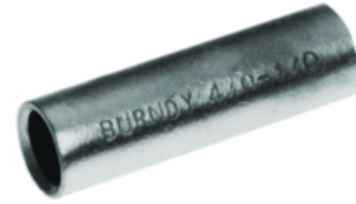

## Application

Wire Reducing Splice Adapter Insert

## General

Color Code	Purple
Connector Type	LONG BARREL
Die Index	15
Feature - Barrel Type	Long
Finish Type	Tin-Plated
Material	COPPER
Plated	Y
Plating Type	Tin Plated
Temperature Rating	194
UPC	781810035405
UPC 12 Digit	7818100354055

## Dimensions

Dimension - B Length inch	1.75 in
Dimension - L Length Overall mm	44 mm
Dimension - Length Overall inch	1.75 in
Dimension - Outside Diameter inch	0.534 in

## Electrical Ratings

Voltage - Maximum	35000
-------------------	-------

## Conductor Related

Conductor - Copper Str Run	4/0 AWG
Conductor - Copper Str Run Range	4/0 AWG
Conductor - Copper Str Size Range	6 AWG
Conductor - Copper Str Tap	6 AWG
Conductor - Copper Str Tap Range	8 AWG-6 AWG
Conductor - Material	COPPER
Conductor Type	CODE
Wire Size	#6 AWG

## Certifications And Compliance

Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No
Standards - RoHS Compliance Status	CM
UL Listed	No

## Logistics

Carton Quantity	100
Minimum Pack Quantity	10
Pallet Quantity	17400

## Product Assets

[Catalogs - Full Line BURNDY Catalog](#)  
[Customer Notices - Prop 65 Notice](#)  
[Sales Drawings - SD..016040-01](#)