


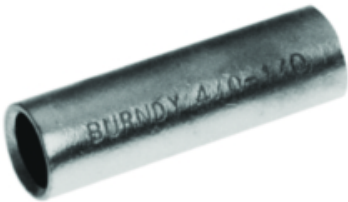

Compression Splice Reducer

By Burndy
Catalog # [Y286CR](#)

4/0 AWG CU Long Barrel Size Reduced Down To 6 AWG Wire Size, Internal Chamfer, Tin Plated, Up to 35kV, PURPLE Color Code, 15 Die Index.



Application

Wire Reducing Splice Adapter Insert

General

Color Code	Purple
Connector Type	LONG BARREL
Die Index	15
Feature - Barrel Type	Long
Finish Type	Tin-Plated
Material	COPPER
Plated	Y
Plating Type	Tin Plated
Temperature Rating	194
UPC	781810035405
UPC 12 Digit	7818100354055

Dimensions

Dimension - B Length inch	1.75 in
Dimension - L Length Overall mm	44 mm
Dimension - Length Overall inch	1.75 in
Dimension - Outside Diameter inch	0.534 in

Electrical Ratings

Voltage - Maximum	35000
-------------------	-------

Conductor Related

Conductor - Copper Str Run	4/0 AWG
Conductor - Copper Str Run Range	4/0 AWG
Conductor - Copper Str Size Range	6 AWG
Conductor - Copper Str Tap	6 AWG
Conductor - Copper Str Tap Range	8 AWG-6 AWG
Conductor - Material	COPPER
Conductor Type	CODE
Wire Size	#6 AWG

Certifications And Compliance

Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No
Standards - RoHS Compliance Status	CM
UL Listed	No

Logistics

Carton Quantity	100
Minimum Pack Quantity	10
Pallet Quantity	17400

Product Assets

[Catalogs - Full Line BURNDY Catalog](#)
[Customer Notices - Prop 65 Notice](#)
[Sales Drawings - SD..016040-01](#)



A proud member of the Hubbell Family.