


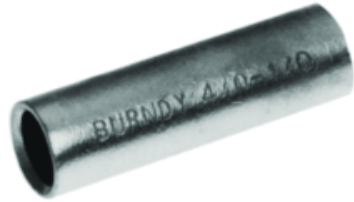

# Compression Splice Reducer

By Burndy  
Catalog # [Y2928R](#)

250 kcmil CU Long Barrel Size Reduced Down To 4/0 AWG Wire Size, Internal Chamfer, Tin Plated, Up to 35kV, YELLOW Color Code, 16 Die Index.



### Application

Wire Reducing Splice Adapter Insert

### General

Color Code	Yellow
Connector Type	LONG BARREL
Die Index	16
EU RoHS Indicator	Yes
Feature - Barrel Type	Long
Finish Type	Tin-Plated
Material	COPPER
Plated	Y
Plating Type	Tin - Electro Plated
Sub Brand	REDUCER/ADAPTER
Temperature Rating	194
Type	Y-R, Compression
UPC	781810085196
UPC 12 Digit	7818100851966

### Dimensions

Dimension - B Length inch	1.62 in
Dimension - L Length Overall mm	41 mm
Dimension - Length Overall inch	1.62 in
Dimension - Outside Diameter inch	0.592 in

### Electrical Ratings

Voltage - Maximum	35000
-------------------	-------

### Conductor Related

Conductor - Copper Str Run	250 kcmil
Conductor - Copper Str Run Range	250 kcmil
Conductor - Copper Str Size Range	4/0 AWG
Conductor - Copper Str Tap	4/0 AWG
Conductor - Copper Str Tap Range	4/0 AWG
Conductor - Material	COPPER
Conductor Type	CODE
Wire Size	#4/0 AWG

### Certifications And Compliance

Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No
Standards - RoHS Compliance Status	CM
UL Listed	No

### Logistics

Carton Quantity	100
Minimum Pack Quantity	1
Pallet Quantity	39200

### Product Assets

[Catalogs - Full Line BURNDY Catalog](#)  
[Customer Notices - Prop 65 Notice](#)  
[Sales Drawings - SD..016040-01](#)



A proud member of the Hubbell Family.