


# Y3130R, Compression Splice Reducer, Barrel A 350 kcmil, Barrel B 300 kcmil

By Burndy  
Catalog # Y3130R

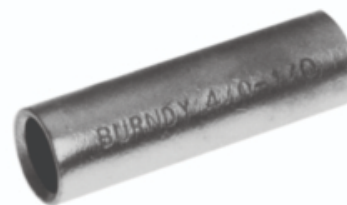

350 kcmil CU Long Barrel Size Reduced Down To 300 kcmil Wire Size, Internal Chamfer, Tin Plated, Up to 35kV, RED Color Code, 18 or 324 Die Index.

## Features

Copper reducing sleeve that allows a larger terminal or splice to accommodate a smaller wire gauge

## Application

Wire Reducing Splice Adapter Insert

## General

|                        |               |
|------------------------|---------------|
| Catalog Number         | Y3130R        |
| Color Code             | Brown         |
| Connector Type         | LONG BARREL   |
| Die Index              | 18            |
| Feature - Barrel Style | Chamfered     |
| Feature - Barrel Type  | Long          |
| Finish Type            | Tin-Plated    |
| Material               | COPPER        |
| Plated                 | Y             |
| Plating Type           | Tin Plated    |
| Temperature Rating     | 194           |
| UPC                    | 781810050767  |
| UPC 12 Digit           | 7818100507677 |

## Dimensions

|                                   |          |
|-----------------------------------|----------|
| Dimension - B Length inch         | 2.00 in  |
| Dimension - Inside Diameter inch  | 0.65 in  |
| Dimension - L Length Overall mm   | 51 mm    |
| Dimension - Length Overall inch   | 2.00 in  |
| Dimension - Outside Diameter inch | 0.687 in |

## Electrical Ratings

|                   |       |
|-------------------|-------|
| Voltage - Maximum | 35000 |
|-------------------|-------|

## Conductor Related

|                                   |           |
|-----------------------------------|-----------|
| Conductor - Copper Str Run        | 350 kcmil |
| Conductor - Copper Str Size       | 300 kcmil |
| Conductor - Copper Str Size Range | 300 kcmil |
| Conductor - Copper Str Tap        | 300 KCMIL |
| Conductor - Material              | COPPER    |
| Conductor Type                    | CODE      |

## Certifications And Compliance

|                               |    |
|-------------------------------|----|
| Certification - CSA Approved  | No |
| Certification - ETL           | No |
| Certification - UL Recognized | No |
| Certification - cULus         | No |
| Standards - RoHS Compliance   | CM |
| Status                        |    |
| UL Listed                     | No |

## Logistics

|                       |       |
|-----------------------|-------|
| Carton Quantity       | 100   |
| Minimum Pack Quantity | 100   |
| Pallet Quantity       | 46400 |

## Product Assets

- [Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)
- [Customer Notices - Prop 65 Notice](#)
- [Interactive Catalog - BURNDY Full-Line Digital Catalog](#)
- [Sales Drawings - SD..016040-01](#)