


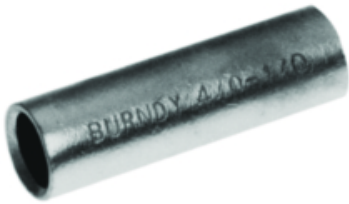

Compression Splice Reducer

By Burndy
Catalog # [Y3427R](#)

500 kcmil CU Long Barrel Size Reduced Down To 3/0 AWG Wire Size, Internal Chamfer, Tin Plated, Up to 35kV, BROWN Color Code, 20 or 299 Die Index.



Application

Wire Reducing Splice Adapter Insert

General

Color Code	Brown
Connector Type	LONG BARREL
Die Index	20
Feature - Barrel Type	Long
Finish Type	Tin-Plated
Material	COPPER
Plated	Y
Plating Type	Tin Plated
Temperature Rating	194
UPC	781810001066
UPC 12 Digit	7818100010666

Dimensions

Dimension - B Length inch	2.50 in
Dimension - L Length Overall mm	64 mm
Dimension - Length Overall inch	2.50 in
Dimension - Outside Diameter inch	0.821 in

Electrical Ratings

Voltage - Maximum	35000
-------------------	-------

Conductor Related

Conductor - Copper Str Run	500 kcmil
Conductor - Copper Str Run Range	500 kcmil
Conductor - Copper Str Size Range	3/0 AWG
Conductor - Copper Str Tap	3/0 AWG
Conductor - Copper Str Tap Range	3/0 AWG
Conductor - Material	COPPER
Conductor Type	CODE
Wire Size	#3/0 AWG

Certifications And Compliance

Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No
Standards - RoHS Compliance Status	CM
UL Listed	No

Logistics

Carton Quantity	50
Minimum Pack Quantity	1
Pallet Quantity	5800

Product Assets

[Catalogs - Full Line BURNDY Catalog](#)
[Customer Notices - Prop 65 Notice](#)
[Sales Drawings - SD..016040-01](#)



A proud member of the Hubbell Family.