


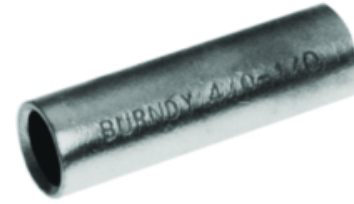

# Compression Splice Reducer

By Burndy  
Catalog # Y3934R

750 kcmil CU Long Barrel Size Reduced Down To 500 kcmil Wire Size, Internal Chamfer, Tin Plated, Up to 35kV, BLACK Color Code, 24 Die Index.



## Application

Wire Reducing Splice Adapter Insert

## General

Color Code	Black
Connector Type	LONG BARREL
Die Index	24
EU RoHS Indicator	Yes
Feature - Barrel Style	Chamfered
Feature - Barrel Type	Long
Finish Type	Tin-Plated
Material	COPPER
Plated	Y
Plating Type	Tin Plated
Sub Brand	REDUCER/ADAPTER
Temperature Rating	194
Type	Y-R, Compression
UPC	781810001127
UPC 12 Digit	7818100011277

## Dimensions

Dimension - B Length inch	2.88 in
Dimension - Inside Diameter inch	0.83 in
Dimension - L Length Overall mm	73 mm
Dimension - Length Overall inch	2.88 in
Dimension - Outside Diameter inch	1.017 in

## Electrical Ratings

Voltage - Maximum	35000
-------------------	-------

## Conductor Related

Conductor - Copper Str Run	750 kcmil
Conductor - Copper Str Size	500 kcmil
Conductor - Copper Str Size Range	500 kcmil
Conductor - Copper Str Tap	500 KCMIL
Conductor - Material	COPPER
Conductor Type	CODE
Wire Size	500 kcmil

## Certifications And Compliance

Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No
Standards - RoHS Compliance Status	CM
UL Listed	No

## Logistics

Carton Quantity	25
Minimum Pack Quantity	1
Pallet Quantity	8700

## Product Assets

[Catalogs - Full Line BURNDY Catalog](#)  
[Customer Notices - Prop 65 Notice](#)  
[Sales Drawings - SD..016040-01](#)



A proud member of the Hubbell Family.