


# YA292NT38, Compression Terminal, 250 kcmil Cu, 2-Hole, 3/8" Stud, 1" Spacing, Long Barrel, Narrow Tongue

By Burndy  
Catalog # [YA292NT38](#)

250 kcmil CU, Two Hole, 3/8 Stud Size, 1 Hole Spacing, Long Barrel, Narrow Tongue Internal Chamfer, Tin Plated, UL/CSA, 90°C, Up to 35kV, Yellow Color Code, 16 Die Index.

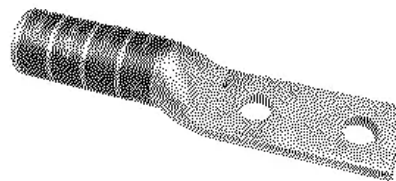

## Features

- Barrel designed with internal chamfer at wire entry for smooth insertion of wire, preventing possible damage of the strands
- Long barrel length allows for an increased number of crimps increasing the mechanical strength of the connection
- Electro-tin plated unless otherwise specified to reduce galvanic corrosion (bimetallic) and resist corrosive elements
- Connectors are clearly marked with stamping and barrel color coding
- 2-Hole design prevents rotation

## Application

Wire Termination

## General

Catalog Number	YA292NT38
Color Code	Yellow
Connector Type	LONG BARREL
Die Index	16
Feature - Barrel Style	Chamfered
Finish Type	Tin-Plated
Material	COPPER
Physical Attribute - Number of Holes	2
Plated	Y
Plating Type	Tin
Trade Name	HYLUG™
UPC	781810672723

## Dimensions

Dimension - B Length fraction	1-5/8 in
Dimension - B Length inch	1.62 in
Dimension - Bolt Hole Size inch	0.41 in
Dimension - Bolt Size fraction	3/8
Dimension - Bolt Size inch	0.38
Dimension - Hole Size fraction	3/8
Dimension - Hole Size inch	0.41
Dimension - Hole Size mm	10.4 mm

Dimension - L Length Overall mm	102 mm
Dimension - Length Overall inch	4.02 in
Dimension - Outside Diameter inch	0.75 in
Dimension - Pad Width inch	0.76 in
Dimension - Strip Length inch	1-11/16 in
Dimension - Stud Size fraction	3/8
Dimension - Stud Size inch	3/8 in
Physical Attribute - Tongue Angle	Straight

## Electrical Ratings

Voltage - Maximum	35000
Voltage Rating	35 kV

## Conductor Related

Conductor - Copper DLO Size Range	N/A
Conductor - Copper Str Navy Size	250 (61)
Conductor - Copper Str Size	250 KCMIL
Conductor - Copper Str Size Range	250 kcmil
Conductor - Material	COPPER
Conductor Size	250 KCMIL
Conductor Type	CODE

## Certifications And Compliance

Certification - CSA Approved Industry Standard(s)	Yes UL 486A-486B
Standards - RoHS Compliance Status	CM
UL Listed	Yes

## Logistics

Carton Quantity	25
Minimum Pack Quantity	1

Pallet Quantity

9600

Installation Manuals - Copper Code Long Terminals Tooling and Installation Instructions

Interactive Catalog - BURNDY Full-Line Digital Catalog

Sales Drawings - 50046230

Specifications - YA292NT38

Video - HYDENT Compression Terminal Overview Video

**Product Assets**

Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog

Catalogs - BURNDY Master Catalog - Section C - Compression Connections



A Hubbell brand

©2024 Hubbell Incorporated. All rights reserved  
BRDY-YA292NT38-SPEC-EN | REV 10/2024